


**AB-PB-M12MS-5,0PUR**
**Article No.:** 22260768

Pre-assembled bus cable; Cable chain, Flexible; PROFIBUS DP; SF/UTP; Polyurethane; 1x2; Open end; M 12 (B-coded), Plug, Straight (180 °); 5 m

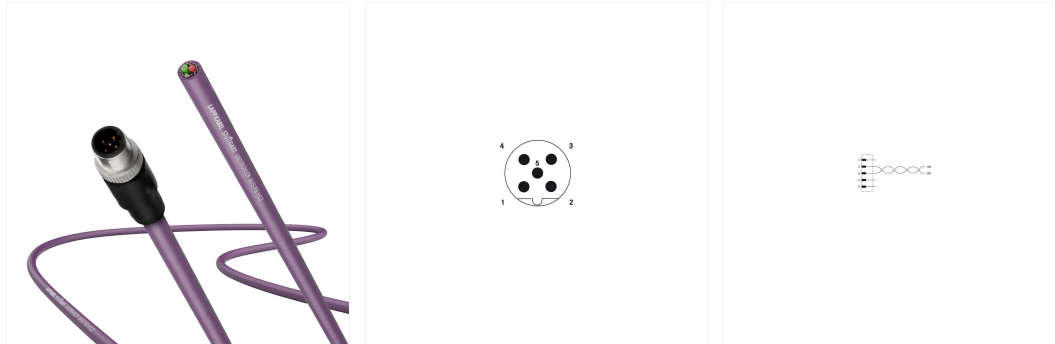

## Details

### Notes

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

### Remarks

## Technical Data

### General information

|               |                               |
|---------------|-------------------------------|
| Brand         | UNITRONIC®                    |
| Product type  | Pre-assembled bus cable       |
| Length        | 5 m                           |
| Delivery Unit | 1                             |
| Connector 1   | M 12; Plug; Straight; B-coded |

|                                   |             |
|-----------------------------------|-------------|
| Connector 2                       | Open end    |
| valid Fieldbus or Ethernet System | PROFIBUS DP |

### Electrical parameters

#### Product design

|  |     |
|--|-----|
| Cable dimension                          | 2X  |
| Number of cores                          | 2   |
| Shielded                                 | No  |
| Base material of outer sheath, shortname | PUR |

#### Product features

|                              |                |
|------------------------------|----------------|
| Application area             | Cable chain    |
| IP protection rating         | IP 65<br>IP 67 |
| Suitable for EX-applications | No             |

#### Certifications and standards

|                          |                      |
|--------------------------|----------------------|
| CE marking               | No                   |
| EAC certified            | Not required         |
| EAC certification number | Отказное письмо № 40 |
| UL recognized            | No                   |
| UL listed                | No                   |
| cUR recognized           | No                   |
| cUL listed               | No                   |
| CSA certified            | No                   |
| VDE certified            | No                   |
| DNV-certified            | No                   |
| Ecolab certified         | No                   |

**UNITRONIC® BUS PB Cordsets**

| Article No. | Name                      | Connector 1                   | Connector 2                     | Length | Number of cores |
|-------------|---------------------------|-------------------------------|---------------------------------|--------|-----------------|
| 22260079    | AB-PB-M12MA-5,0PUR-M12FA  | M 12; Plug; Angled; B-coded   | M 12; Socket; Angled; B-coded   | 5 m    | 2               |
| 22260767    | AB-PB-M12MS-2,0PUR        | M 12; Plug; Straight; B-coded | Open end                        | 2 m    | 2               |
| 22260768    | AB-PB-M12MS-5,0PUR        | M 12; Plug; Straight; B-coded | Open end                        | 5 m    | 2               |
| 22260769    | AB-PB-M12MS-10,0PUR       | M 12; Plug; Straight; B-coded | Open end                        | 10 m   | 2               |
| 22260770    | AB-PB-2,0PUR-M12FS        | Open end                      | M 12; Socket; Straight; B-coded | 2 m    | 2               |
| 22260771    | AB-PB-5,0PUR-M12FS        | Open end                      | M 12; Socket; Straight; B-coded | 5 m    | 2               |
| 22260772    | AB-PB-10,0PUR-M12FS       | Open end                      | M 12; Socket; Straight; B-coded | 10 m   | 2               |
| 22260773    | AB-PB-M12MS-0,3PUR-M12FS  | M 12; Plug; Straight; B-coded | M 12; Socket; Straight; B-coded | 0.3 m  | 2               |
| 22260774    | AB-PB-M12MS-1,0PUR-M12FS  | M 12; Plug; Straight; B-coded | M 12; Socket; Straight; B-coded | 1 m    | 2               |
| 22260775    | AB-PB-M12MS-2,0PUR-M12FS  | M 12; Plug; Straight; B-coded | M 12; Socket; Straight; B-coded | 2 m    | 2               |
| 22260776    | AB-PB-M12MS-5,0PUR-M12FS  | M 12; Plug; Straight; B-coded | M 12; Socket; Straight; B-coded | 5 m    | 2               |
| 22260777    | AB-PB-M12MS-10,0PUR-M12FS | M 12; Plug; Straight; B-coded | M 12; Socket; Straight; B-coded | 10 m   | 2               |
| 22260869    | AB-PB-M12MS-3,0PUR-M12FS  | M 12; Plug; Straight; B-coded | M 12; Socket; Straight; B-coded | 3 m    | 2               |
| 22260904    | AB-PB-M12MA-10,0PUR-M12FA | M 12; Plug; Angled; B-coded   | M 12; Socket; Angled; B-coded   | 10 m   | 2               |
| 22260905    | AB-PB-M12MA-15,0PUR-M12FA | M 12; Plug; Angled; B-coded   | M 12; Socket; Angled; B-coded   | 15 m   | 2               |
| 22260907    | AB-PB-M12MS-15,0PUR-M12FS | M 12; Plug; Straight; B-coded | M 12; Socket; Straight; B-coded | 15 m   | 2               |
| 22260908    | AB-PB-M12MS-20,0PUR-M12FS | M 12; Plug; Straight; B-coded | M 12; Socket; Straight; B-coded | 20 m   | 2               |
| 22260955    | AB-PB-M12MS-0,2PUR-M12FS  | M 12; Plug; Straight; B-coded | M 12; Socket; Straight; B-coded | 0.2 m  | 2               |
| 22260956    | AB-PB-M12MA-2,0PUR        | M 12; Plug; Angled; B-coded   | Open end                        | 2 m    | 2               |

V1.1