


AB-PB-M12MS-2,0PUR-M12FS

Article No.: 22260775

Pre-assembled bus cable; Cable chain, Flexible; PROFIBUS DP; SF/UTP; Polyurethane; 1x2; M 12 (B-coded), Plug, Straight (180 °); M 12 (B-coded), Socket, Straight (180 °); 2 m

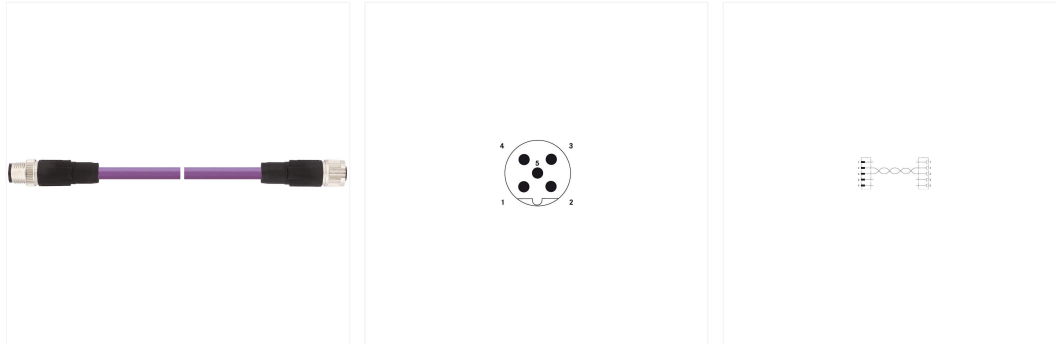

Details

Notes

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Remarks

Technical Data

General information

Brand	UNITRONIC®
Product type	Pre-assembled bus cable
Length	2 m
Delivery Unit	1

Connector 1	M 12; Plug; Straight; B-coded
Connector 2	M 12; Socket; Straight; B-coded
valid Fieldbus or Ethernet System	PROFIBUS DP

Electrical parameters**Product design**

Cable dimension	2X
Number of cores	2
Shielded	Yes
Base material of outer sheath, shortname	PUR

Product features

Application area	Cable chain
IP protection rating	IP 65 IP 67
Suitable for EX-applications	No

Certifications and standards

CE marking	No
EAC certified	Not required
EAC certification number	Отказное письмо № 40
UL recognized	No
UL listed	No
cUR recognized	No
cUL listed	No
CSA certified	No
VDE certified	No
DNV-certified	No
Ecolab certified	No

UNITRONIC® BUS PB Cordsets

Article No.	Name	Connector 1	Connector 2	Length	Number of cores
22260079	AB-PB-M12MA-5,0PUR-M12FA	M 12; Plug; Angled; B-coded	M 12; Socket; Angled; B-coded	5 m	2
22260767	AB-PB-M12MS-2,0PUR	M 12; Plug; Straight; B-coded	Open end	2 m	2
22260768	AB-PB-M12MS-5,0PUR	M 12; Plug; Straight; B-coded	Open end	5 m	2
22260769	AB-PB-M12MS-10,0PUR	M 12; Plug; Straight; B-coded	Open end	10 m	2
22260770	AB-PB-2,0PUR-M12FS	Open end	M 12; Socket; Straight; B-coded	2 m	2
22260771	AB-PB-5,0PUR-M12FS	Open end	M 12; Socket; Straight; B-coded	5 m	2
22260772	AB-PB-10,0PUR-M12FS	Open end	M 12; Socket; Straight; B-coded	10 m	2
22260773	AB-PB-M12MS-0,3PUR-M12FS	M 12; Plug; Straight; B-coded	M 12; Socket; Straight; B-coded	0.3 m	2
22260774	AB-PB-M12MS-1,0PUR-M12FS	M 12; Plug; Straight; B-coded	M 12; Socket; Straight; B-coded	1 m	2
22260775	AB-PB-M12MS-2,0PUR-M12FS	M 12; Plug; Straight; B-coded	M 12; Socket; Straight; B-coded	2 m	2
22260776	AB-PB-M12MS-5,0PUR-M12FS	M 12; Plug; Straight; B-coded	M 12; Socket; Straight; B-coded	5 m	2
22260777	AB-PB-M12MS-10,0PUR-M12FS	M 12; Plug; Straight; B-coded	M 12; Socket; Straight; B-coded	10 m	2
22260869	AB-PB-M12MS-3,0PUR-M12FS	M 12; Plug; Straight; B-coded	M 12; Socket; Straight; B-coded	3 m	2
22260904	AB-PB-M12MA-10,0PUR-M12FA	M 12; Plug; Angled; B-coded	M 12; Socket; Angled; B-coded	10 m	2
22260905	AB-PB-M12MA-15,0PUR-M12FA	M 12; Plug; Angled; B-coded	M 12; Socket; Angled; B-coded	15 m	2
22260907	AB-PB-M12MS-15,0PUR-M12FS	M 12; Plug; Straight; B-coded	M 12; Socket; Straight; B-coded	15 m	2
22260908	AB-PB-M12MS-20,0PUR-M12FS	M 12; Plug; Straight; B-coded	M 12; Socket; Straight; B-coded	20 m	2
22260955	AB-PB-M12MS-0,2PUR-M12FS	M 12; Plug; Straight; B-coded	M 12; Socket; Straight; B-coded	0.2 m	2
22260956	AB-PB-M12MA-2,0PUR	M 12; Plug; Angled; B-coded	Open end	2 m	2

V1.1