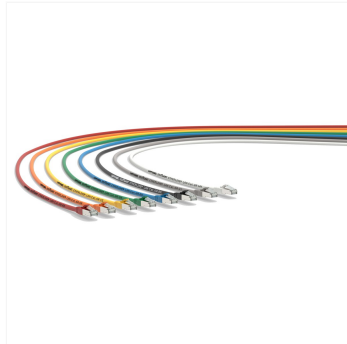


ETHERLINE® LAN Cat.6A 1,5 BU**Article No.:** 24441334

Pre-assembled Ethernet cable; Flexible; Ethernet; Cat.6A; S/FTP; 4x2; RJ45, Plug, Straight (180 °); RJ45, Plug, Straight (180 °); 1.5 m

**Details****Benefits**

- Rapid information exchange at up to 10 Gbit/s over 60 m (196.86 ft) thanks to Cat. 6A Ethernet.
- Cable assembled on both sides saves time and eliminates the potential for errors during on-site assembly. Professional conductor connection according to defined criteria ensures consistent product quality.
- The narrow RJ45 connector allows use in devices with a very high port density.
- Ideal protection against electromagnetic interference due to pair shielding with aluminum compound foil and copper shielding braiding as overall shielding (S/FTP).
- UL/CSA certification according to technical data enables the product to be used on the North American market.
- With halogen free LSZH outer jacket to meet special fire protection requirements.
- Versatile properties allow universal use, reduce the variety of parts and thus result in savings in logistics.
- Available in different colors.

Application

- For structured building cabling according to DIN EN 50173 and ISO/IEC 11801.
- Suitable for workplace cabling.

- Can also be used in industrial control cabinets, taking electromagnetic stress into account.
- Suitable for Ethernet applications up to 10GBase-T.

Notes

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Remarks

Technical Data

General information

Brand	ETHERLINE®
Product type	Pre-assembled Ethernet cable
Length	1.5 m
Delivery Unit	1
Connector 1	RJ45; Plug; Straight; Number of contacts: 8
Connector 2	RJ45; Plug; Straight; Number of contacts: 8
valid Fieldbus or Ethernet System	Ethernet ETHERNET/IP
Industry segment	Agricultural & Farm Machinery Assembly Machines Food & Beverage Healthcare & Pharma Intralogistics & Material handling Machine Tools Packaging Ships & boats

Electrical parameters

Product design

Cable dimension	8X
Number of cores	8
Shielded	Yes
Base material of outer sheath, shortname	LSZH
Outer jacket color	blue

Product features

Application area	Flexible
Min. number of insertion cycles	750 / 750
IP protection rating	IP 20
Suitable for EX-applications	No
Installation temperature min.	0 °C
Max. assembly temperature	50 °C
Storage temperature max.	-20 °C
Storage temperature maximum	60 °C
Ethernet cable category	Cat.6A

Certifications and standards

CE marking	Yes
EAC certified	Not required
EAC certification number	Отказное письмо № 40
UL recognized	No
UL listed	Yes
UL certification	according to UL 1863 (e-file number: E353543-DUXR)
cUR recognized	No
cUL listed	Yes
CSA certified	No
VDE certified	No
Product standard according to IEC	RJ45 according to IEC 60603-7-51
DNV-certified	No
Ecolab certified	No

ETHERLINE® LAN Cat.6A patchcords

Article No.	Name	Connector 1	Connector 2	Length	Outer jacket color
24441316	ETHERLINE® LAN Cat.6A 0,25 BK	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.25 m	black
24441317	ETHERLINE® LAN Cat.6A 0,5 BK	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.5 m	black
24441318	ETHERLINE® LAN Cat.6A 1,0 BK	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1 m	black
24441319	ETHERLINE® LAN Cat.6A 1,5 BK	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1.5 m	black
24441320	ETHERLINE® LAN Cat.6A 2,0 BK	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	2 m	black
24441321	ETHERLINE® LAN Cat.6A 3,0 BK	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	3 m	black
24441322	ETHERLINE® LAN Cat.6A 5,0 BK	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	5 m	black
24441323	ETHERLINE® LAN Cat.6A 7,5 BK	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	7.5 m	black
24441324	ETHERLINE® LAN Cat.6A 10,0 BK	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	10 m	black
24441325	ETHERLINE® LAN Cat.6A 15,0 BK	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	15 m	black
24441326	ETHERLINE® LAN Cat.6A 20,0 BK	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	20 m	black
24441327	ETHERLINE® LAN Cat.6A 25,0 BK	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	25 m	black
24441328	ETHERLINE® LAN Cat.6A 30,0 BK	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	30 m	black
24441329	ETHERLINE® LAN Cat.6A 40,0 BK	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	40 m	black
24441330	ETHERLINE® LAN Cat.6A 50,0 BK	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	50 m	black
24441331	ETHERLINE® LAN Cat.6A 0,25 BU	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.25 m	blue
24441332	ETHERLINE® LAN Cat.6A 0,5 BU	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.5 m	blue
24441333	ETHERLINE® LAN Cat.6A 1,0 BU	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1 m	blue
24441334	ETHERLINE® LAN Cat.6A 1,5 BU	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1.5 m	blue
24441335	ETHERLINE® LAN Cat.6A 2,0 BU	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	2 m	blue
24441336	ETHERLINE® LAN Cat.6A 3,0 BU	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	3 m	blue
24441337	ETHERLINE® LAN Cat.6A 5,0 BU	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	5 m	blue
24441338	ETHERLINE® LAN Cat.6A 7,5 BU	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	7.5 m	blue
24441339	ETHERLINE® LAN Cat.6A 10,0 BU	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	10 m	blue
24441340	ETHERLINE® LAN Cat.6A 15,0 BU	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	15 m	blue
24441341	ETHERLINE® LAN Cat.6A 20,0 BU	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	20 m	blue
24441342	ETHERLINE® LAN Cat.6A 25,0 BU	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	25 m	blue
24441343	ETHERLINE® LAN Cat.6A 30,0 BU	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	30 m	blue
24441344	ETHERLINE® LAN Cat.6A 40,0 BU	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	40 m	blue
24441345	ETHERLINE® LAN Cat.6A 50,0 BU	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	50 m	blue

Article No.	Name	Connector 1	Connector 2	Length	Outer jacket color
24441346	ETHERLINE® LAN Cat.6A 0,25 GN	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.25 m	green
24441347	ETHERLINE® LAN Cat.6A 0,5 GN	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.5 m	green
24441348	ETHERLINE® LAN Cat.6A 1,0 GN	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1 m	green
24441349	ETHERLINE® LAN Cat.6A 1,5 GN	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1.5 m	green
24441350	ETHERLINE® LAN Cat.6A 2,0 GN	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	2 m	green
24441351	ETHERLINE® LAN Cat.6A 3,0 GN	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	3 m	green
24441352	ETHERLINE® LAN Cat.6A 5,0 GN	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	5 m	green
24441353	ETHERLINE® LAN Cat.6A 7,5 GN	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	7.5 m	green
24441354	ETHERLINE® LAN Cat.6A 10,0 GN	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	10 m	green
24441355	ETHERLINE® LAN Cat.6A 15,0 GN	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	15 m	green
24441356	ETHERLINE® LAN Cat.6A 20,0 GN	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	20 m	green
24441357	ETHERLINE® LAN Cat.6A 25,0 GN	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	25 m	green
24441358	ETHERLINE® LAN Cat.6A 30,0 GN	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	30 m	green
24441359	ETHERLINE® LAN Cat.6A 40,0 GN	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	40 m	green
24441360	ETHERLINE® LAN Cat.6A 50,0 GN	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	50 m	green
24441361	ETHERLINE® LAN Cat.6A 0,25 GY	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.25 m	gray
24441362	ETHERLINE® LAN Cat.6A 0,5 GY	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.5 m	gray
24441363	ETHERLINE® LAN Cat.6A 1,0 GY	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1 m	gray
24441364	ETHERLINE® LAN Cat.6A 1,5 GY	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1.5 m	gray
24441365	ETHERLINE® LAN Cat.6A 2,0 GY	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	2 m	gray
24441366	ETHERLINE® LAN Cat.6A 3,0 GY	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	3 m	gray
24441367	ETHERLINE® LAN Cat.6A 5,0 GY	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	5 m	gray
24441368	ETHERLINE® LAN Cat.6A 7,5 GY	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	7.5 m	gray
24441369	ETHERLINE® LAN Cat.6A 10,0 GY	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	10 m	gray
24441370	ETHERLINE® LAN Cat.6A 15,0 GY	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	15 m	gray
24441371	ETHERLINE® LAN Cat.6A 20,0 GY	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	20 m	gray
24441372	ETHERLINE® LAN Cat.6A 25,0 GY	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	25 m	gray
24441373	ETHERLINE® LAN Cat.6A 30,0 GY	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	30 m	gray
24441374	ETHERLINE® LAN Cat.6A 40,0 GY	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	40 m	gray
24441375	ETHERLINE® LAN Cat.6A 50,0 GY	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	50 m	gray

Article No.	Name	Connector 1	Connector 2	Length	Outer jacket color
24441376	ETHERLINE® LAN Cat.6A 0,25 OR	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.25 m	orange
24441377	ETHERLINE® LAN Cat.6A 0,5 OR	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.5 m	orange
24441378	ETHERLINE® LAN Cat.6A 1,0 OR	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1 m	orange
24441379	ETHERLINE® LAN Cat.6A 1,5 OR	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1.5 m	orange
24441380	ETHERLINE® LAN Cat.6A 2,0 OR	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	2 m	orange
24441381	ETHERLINE® LAN Cat.6A 3,0 OR	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	3 m	orange
24441382	ETHERLINE® LAN Cat.6A 5,0 OR	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	5 m	orange
24441383	ETHERLINE® LAN Cat.6A 7,5 OR	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	7.5 m	orange
24441384	ETHERLINE® LAN Cat.6A 10,0 OR	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	10 m	orange
24441385	ETHERLINE® LAN Cat.6A 15,0 OR	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	15 m	orange
24441386	ETHERLINE® LAN Cat.6A 20,0 OR	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	20 m	orange
24441387	ETHERLINE® LAN Cat.6A 25,0 OR	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	25 m	orange
24441388	ETHERLINE® LAN Cat.6A 30,0 OR	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	30 m	orange
24441389	ETHERLINE® LAN Cat.6A 40,0 OR	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	40 m	orange
24441390	ETHERLINE® LAN Cat.6A 50,0 OR	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	50 m	orange
24441391	ETHERLINE® LAN Cat.6A 0,25 RD	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.25 m	red
24441392	ETHERLINE® LAN Cat.6A 0,5 RD	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.5 m	red
24441393	ETHERLINE® LAN Cat.6A 1,0 RD	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1 m	red
24441394	ETHERLINE® LAN Cat.6A 1,5 RD	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1.5 m	red
24441395	ETHERLINE® LAN Cat.6A 2,0 RD	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	2 m	red
24441396	ETHERLINE® LAN Cat.6A 3,0 RD	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	3 m	red
24441397	ETHERLINE® LAN Cat.6A 5,0 RD	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	5 m	red
24441398	ETHERLINE® LAN Cat.6A 7,5 RD	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	7.5 m	red
24441399	ETHERLINE® LAN Cat.6A 10,0 RD	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	10 m	red
24441400	ETHERLINE® LAN Cat.6A 15,0 RD	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	15 m	red
24441401	ETHERLINE® LAN Cat.6A 20,0 RD	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	20 m	red
24441402	ETHERLINE® LAN Cat.6A 25,0 RD	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	25 m	red
24441403	ETHERLINE® LAN Cat.6A 30,0 RD	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	30 m	red
24441404	ETHERLINE® LAN Cat.6A 40,0 RD	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	40 m	red
24441405	ETHERLINE® LAN Cat.6A 50,0 RD	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	50 m	red

Article No.	Name	Connector 1	Connector 2	Length	Outer jacket color
24441406	ETHERLINE® LAN Cat.6A 0,25 WH	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.25 m	white
24441407	ETHERLINE® LAN Cat.6A 0,5 WH	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.5 m	white
24441408	ETHERLINE® LAN Cat.6A 1,0 WH	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1 m	white
24441409	ETHERLINE® LAN Cat.6A 1,5 WH	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1.5 m	white
24441410	ETHERLINE® LAN Cat.6A 2,0 WH	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	2 m	white
24441411	ETHERLINE® LAN Cat.6A 3,0 WH	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	3 m	white
24441412	ETHERLINE® LAN Cat.6A 5,0 WH	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	5 m	white
24441413	ETHERLINE® LAN Cat.6A 7,5 WH	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	7.5 m	white
24441414	ETHERLINE® LAN Cat.6A 10,0 WH	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	10 m	white
24441415	ETHERLINE® LAN Cat.6A 15,0 WH	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	15 m	white
24441416	ETHERLINE® LAN Cat.6A 20,0 WH	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	20 m	white
24441417	ETHERLINE® LAN Cat.6A 25,0 WH	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	25 m	white
24441418	ETHERLINE® LAN Cat.6A 30,0 WH	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	30 m	white
24441419	ETHERLINE® LAN Cat.6A 40,0 WH	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	40 m	white
24441420	ETHERLINE® LAN Cat.6A 50,0 WH	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	50 m	white
24441421	ETHERLINE® LAN Cat.6A 0,25 YE	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.25 m	yellow
24441422	ETHERLINE® LAN Cat.6A 0,5 YE	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	0.5 m	yellow
24441423	ETHERLINE® LAN Cat.6A 1,0 YE	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1 m	yellow
24441424	ETHERLINE® LAN Cat.6A 1,5 YE	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	1.5 m	yellow
24441425	ETHERLINE® LAN Cat.6A 2,0 YE	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	2 m	yellow
24441426	ETHERLINE® LAN Cat.6A 3,0 YE	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	3 m	yellow
24441427	ETHERLINE® LAN Cat.6A 5,0 YE	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	5 m	yellow
24441428	ETHERLINE® LAN Cat.6A 7,5 YE	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	7.5 m	yellow
24441429	ETHERLINE® LAN Cat.6A 10,0 YE	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	10 m	yellow
24441430	ETHERLINE® LAN Cat.6A 15,0 YE	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	15 m	yellow
24441431	ETHERLINE® LAN Cat.6A 20,0 YE	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	20 m	yellow
24441432	ETHERLINE® LAN Cat.6A 25,0 YE	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	25 m	yellow
24441433	ETHERLINE® LAN Cat.6A 30,0 YE	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	30 m	yellow
24441434	ETHERLINE® LAN Cat.6A 40,0 YE	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	40 m	yellow
24441435	ETHERLINE® LAN Cat.6A 50,0 YE	RJ45; Plug; Straight; Number of contacts: 8	RJ45; Plug; Straight; Number of contacts: 8	50 m	yellow

V1.1