


ETHERLINE® LAN Cat.6A 2,0 BU

Article No.: 24441335

Pre-assembled Ethernet cable; Flexible; Ethernet; Cat.6A; S/FTP; 4x2; RJ45, Plug, Straight (180 °); RJ45, Plug, Straight (180 °); 2 m

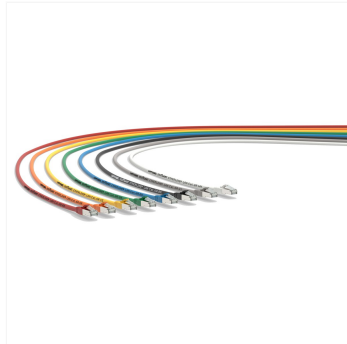

Details

Benefits

- Rapid information exchange at up to 10 Gbit/s over 60 m (196.86 ft) thanks to Cat. 6A Ethernet.
- Cable assembled on both sides saves time and eliminates the potential for errors during on-site assembly. Professional conductor connection according to defined criteria ensures consistent product quality.
- The narrow RJ45 connector allows use in devices with a very high port density.
- Ideal protection against electromagnetic interference due to pair shielding with aluminum compound foil and copper shielding braiding as overall shielding (S/FTP).
- UL/CSA certification according to technical data enables the product to be used on the North American market.
- With halogen free LSZH outer jacket to meet special fire protection requirements.
- Versatile properties allow universal use, reduce the variety of parts and thus result in savings in logistics.
- Available in different colors.

Application

- For structured building cabling according to DIN EN 50173 and ISO/IEC 11801.
- Suitable for workplace cabling.

- Can also be used in industrial control cabinets, taking electromagnetic stress into account.
- Suitable for Ethernet applications up to 10GBase-T.

Notes

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Remarks

Technical Data

General information

| | |
|-----------------------------------|---|
| Brand | ETHERLINE® |
| Product type | Pre-assembled Ethernet cable |
| Length | 2 m |
| Delivery Unit | 1 |
| Connector 1 | RJ45; Plug; Straight; Number of contacts: 8 |
| Connector 2 | RJ45; Plug; Straight; Number of contacts: 8 |
| valid Fieldbus or Ethernet System | Ethernet ETHERNET/IP |
| Industry segment | Agricultural & Farm Machinery Assembly Machines Food & Beverage Healthcare & Pharma Intralogistics & Material handling Machine Tools Packaging Ships & boats |

Electrical parameters

Product design

| | |
|--|------|
| Cable dimension | 8X |
| Number of cores | 8 |
| Shielded | Yes |
| Base material of outer sheath, shortname | LSZH |
| Outer jacket color | blue |

Product features

| | |
|---------------------------------|-----------|
| Application area | Flexible |
| Min. number of insertion cycles | 750 / 750 |
| IP protection rating | IP 20 |
| Suitable for EX-applications | No |
| Installation temperature min. | 0 °C |
| Max. assembly temperature | 50 °C |
| Storage temperature max. | -20 °C |
| Storage temperature maximum | 60 °C |
| Ethernet cable category | Cat.6A |

Certifications and standards

| | |
|-----------------------------------|--|
| CE marking | Yes |
| EAC certified | Not required |
| EAC certification number | Отказное письмо № 40 |
| UL recognized | No |
| UL listed | Yes |
| UL certification | according to UL 1863 (e-file number: E353543-DUXR) |
| cUR recognized | No |
| cUL listed | Yes |
| CSA certified | No |
| VDE certified | No |
| Product standard according to IEC | RJ45 according to IEC 60603-7-51 |
| DNV-certified | No |
| Ecolab certified | No |

ETHERLINE® LAN Cat.6A patchcords

| Article No. | Name | Connector 1 | Connector 2 | Length | Outer jacket color |
|-------------|-------------------------------|---|---|--------|--------------------|
| 24441316 | ETHERLINE® LAN Cat.6A 0,25 BK | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.25 m | black |
| 24441317 | ETHERLINE® LAN Cat.6A 0,5 BK | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.5 m | black |
| 24441318 | ETHERLINE® LAN Cat.6A 1,0 BK | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1 m | black |
| 24441319 | ETHERLINE® LAN Cat.6A 1,5 BK | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1.5 m | black |
| 24441320 | ETHERLINE® LAN Cat.6A 2,0 BK | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 2 m | black |
| 24441321 | ETHERLINE® LAN Cat.6A 3,0 BK | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 3 m | black |
| 24441322 | ETHERLINE® LAN Cat.6A 5,0 BK | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 5 m | black |
| 24441323 | ETHERLINE® LAN Cat.6A 7,5 BK | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 7.5 m | black |
| 24441324 | ETHERLINE® LAN Cat.6A 10,0 BK | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 10 m | black |
| 24441325 | ETHERLINE® LAN Cat.6A 15,0 BK | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 15 m | black |
| 24441326 | ETHERLINE® LAN Cat.6A 20,0 BK | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 20 m | black |
| 24441327 | ETHERLINE® LAN Cat.6A 25,0 BK | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 25 m | black |
| 24441328 | ETHERLINE® LAN Cat.6A 30,0 BK | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 30 m | black |
| 24441329 | ETHERLINE® LAN Cat.6A 40,0 BK | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 40 m | black |
| 24441330 | ETHERLINE® LAN Cat.6A 50,0 BK | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 50 m | black |
| 24441331 | ETHERLINE® LAN Cat.6A 0,25 BU | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.25 m | blue |
| 24441332 | ETHERLINE® LAN Cat.6A 0,5 BU | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.5 m | blue |
| 24441333 | ETHERLINE® LAN Cat.6A 1,0 BU | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1 m | blue |
| 24441334 | ETHERLINE® LAN Cat.6A 1,5 BU | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1.5 m | blue |
| 24441335 | ETHERLINE® LAN Cat.6A 2,0 BU | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 2 m | blue |
| 24441336 | ETHERLINE® LAN Cat.6A 3,0 BU | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 3 m | blue |
| 24441337 | ETHERLINE® LAN Cat.6A 5,0 BU | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 5 m | blue |
| 24441338 | ETHERLINE® LAN Cat.6A 7,5 BU | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 7.5 m | blue |
| 24441339 | ETHERLINE® LAN Cat.6A 10,0 BU | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 10 m | blue |
| 24441340 | ETHERLINE® LAN Cat.6A 15,0 BU | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 15 m | blue |
| 24441341 | ETHERLINE® LAN Cat.6A 20,0 BU | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 20 m | blue |
| 24441342 | ETHERLINE® LAN Cat.6A 25,0 BU | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 25 m | blue |
| 24441343 | ETHERLINE® LAN Cat.6A 30,0 BU | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 30 m | blue |
| 24441344 | ETHERLINE® LAN Cat.6A 40,0 BU | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 40 m | blue |
| 24441345 | ETHERLINE® LAN Cat.6A 50,0 BU | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 50 m | blue |

| Article No. | Name | Connector 1 | Connector 2 | Length | Outer jacket color |
|-------------|-------------------------------|---|---|--------|--------------------|
| 24441346 | ETHERLINE® LAN Cat.6A 0,25 GN | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.25 m | green |
| 24441347 | ETHERLINE® LAN Cat.6A 0,5 GN | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.5 m | green |
| 24441348 | ETHERLINE® LAN Cat.6A 1,0 GN | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1 m | green |
| 24441349 | ETHERLINE® LAN Cat.6A 1,5 GN | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1.5 m | green |
| 24441350 | ETHERLINE® LAN Cat.6A 2,0 GN | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 2 m | green |
| 24441351 | ETHERLINE® LAN Cat.6A 3,0 GN | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 3 m | green |
| 24441352 | ETHERLINE® LAN Cat.6A 5,0 GN | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 5 m | green |
| 24441353 | ETHERLINE® LAN Cat.6A 7,5 GN | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 7.5 m | green |
| 24441354 | ETHERLINE® LAN Cat.6A 10,0 GN | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 10 m | green |
| 24441355 | ETHERLINE® LAN Cat.6A 15,0 GN | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 15 m | green |
| 24441356 | ETHERLINE® LAN Cat.6A 20,0 GN | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 20 m | green |
| 24441357 | ETHERLINE® LAN Cat.6A 25,0 GN | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 25 m | green |
| 24441358 | ETHERLINE® LAN Cat.6A 30,0 GN | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 30 m | green |
| 24441359 | ETHERLINE® LAN Cat.6A 40,0 GN | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 40 m | green |
| 24441360 | ETHERLINE® LAN Cat.6A 50,0 GN | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 50 m | green |
| 24441361 | ETHERLINE® LAN Cat.6A 0,25 GY | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.25 m | gray |
| 24441362 | ETHERLINE® LAN Cat.6A 0,5 GY | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.5 m | gray |
| 24441363 | ETHERLINE® LAN Cat.6A 1,0 GY | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1 m | gray |
| 24441364 | ETHERLINE® LAN Cat.6A 1,5 GY | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1.5 m | gray |
| 24441365 | ETHERLINE® LAN Cat.6A 2,0 GY | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 2 m | gray |
| 24441366 | ETHERLINE® LAN Cat.6A 3,0 GY | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 3 m | gray |
| 24441367 | ETHERLINE® LAN Cat.6A 5,0 GY | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 5 m | gray |
| 24441368 | ETHERLINE® LAN Cat.6A 7,5 GY | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 7.5 m | gray |
| 24441369 | ETHERLINE® LAN Cat.6A 10,0 GY | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 10 m | gray |
| 24441370 | ETHERLINE® LAN Cat.6A 15,0 GY | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 15 m | gray |
| 24441371 | ETHERLINE® LAN Cat.6A 20,0 GY | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 20 m | gray |
| 24441372 | ETHERLINE® LAN Cat.6A 25,0 GY | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 25 m | gray |
| 24441373 | ETHERLINE® LAN Cat.6A 30,0 GY | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 30 m | gray |
| 24441374 | ETHERLINE® LAN Cat.6A 40,0 GY | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 40 m | gray |
| 24441375 | ETHERLINE® LAN Cat.6A 50,0 GY | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 50 m | gray |

| Article No. | Name | Connector 1 | Connector 2 | Length | Outer jacket color |
|-------------|-------------------------------|---|---|--------|--------------------|
| 24441376 | ETHERLINE® LAN Cat.6A 0,25 OR | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.25 m | orange |
| 24441377 | ETHERLINE® LAN Cat.6A 0,5 OR | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.5 m | orange |
| 24441378 | ETHERLINE® LAN Cat.6A 1,0 OR | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1 m | orange |
| 24441379 | ETHERLINE® LAN Cat.6A 1,5 OR | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1.5 m | orange |
| 24441380 | ETHERLINE® LAN Cat.6A 2,0 OR | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 2 m | orange |
| 24441381 | ETHERLINE® LAN Cat.6A 3,0 OR | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 3 m | orange |
| 24441382 | ETHERLINE® LAN Cat.6A 5,0 OR | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 5 m | orange |
| 24441383 | ETHERLINE® LAN Cat.6A 7,5 OR | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 7.5 m | orange |
| 24441384 | ETHERLINE® LAN Cat.6A 10,0 OR | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 10 m | orange |
| 24441385 | ETHERLINE® LAN Cat.6A 15,0 OR | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 15 m | orange |
| 24441386 | ETHERLINE® LAN Cat.6A 20,0 OR | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 20 m | orange |
| 24441387 | ETHERLINE® LAN Cat.6A 25,0 OR | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 25 m | orange |
| 24441388 | ETHERLINE® LAN Cat.6A 30,0 OR | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 30 m | orange |
| 24441389 | ETHERLINE® LAN Cat.6A 40,0 OR | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 40 m | orange |
| 24441390 | ETHERLINE® LAN Cat.6A 50,0 OR | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 50 m | orange |
| 24441391 | ETHERLINE® LAN Cat.6A 0,25 RD | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.25 m | red |
| 24441392 | ETHERLINE® LAN Cat.6A 0,5 RD | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.5 m | red |
| 24441393 | ETHERLINE® LAN Cat.6A 1,0 RD | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1 m | red |
| 24441394 | ETHERLINE® LAN Cat.6A 1,5 RD | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1.5 m | red |
| 24441395 | ETHERLINE® LAN Cat.6A 2,0 RD | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 2 m | red |
| 24441396 | ETHERLINE® LAN Cat.6A 3,0 RD | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 3 m | red |
| 24441397 | ETHERLINE® LAN Cat.6A 5,0 RD | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 5 m | red |
| 24441398 | ETHERLINE® LAN Cat.6A 7,5 RD | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 7.5 m | red |
| 24441399 | ETHERLINE® LAN Cat.6A 10,0 RD | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 10 m | red |
| 24441400 | ETHERLINE® LAN Cat.6A 15,0 RD | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 15 m | red |
| 24441401 | ETHERLINE® LAN Cat.6A 20,0 RD | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 20 m | red |
| 24441402 | ETHERLINE® LAN Cat.6A 25,0 RD | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 25 m | red |
| 24441403 | ETHERLINE® LAN Cat.6A 30,0 RD | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 30 m | red |
| 24441404 | ETHERLINE® LAN Cat.6A 40,0 RD | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 40 m | red |
| 24441405 | ETHERLINE® LAN Cat.6A 50,0 RD | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 50 m | red |

| Article No. | Name | Connector 1 | Connector 2 | Length | Outer jacket color |
|-------------|-------------------------------|---|---|--------|--------------------|
| 24441406 | ETHERLINE® LAN Cat.6A 0,25 WH | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.25 m | white |
| 24441407 | ETHERLINE® LAN Cat.6A 0,5 WH | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.5 m | white |
| 24441408 | ETHERLINE® LAN Cat.6A 1,0 WH | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1 m | white |
| 24441409 | ETHERLINE® LAN Cat.6A 1,5 WH | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1.5 m | white |
| 24441410 | ETHERLINE® LAN Cat.6A 2,0 WH | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 2 m | white |
| 24441411 | ETHERLINE® LAN Cat.6A 3,0 WH | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 3 m | white |
| 24441412 | ETHERLINE® LAN Cat.6A 5,0 WH | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 5 m | white |
| 24441413 | ETHERLINE® LAN Cat.6A 7,5 WH | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 7.5 m | white |
| 24441414 | ETHERLINE® LAN Cat.6A 10,0 WH | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 10 m | white |
| 24441415 | ETHERLINE® LAN Cat.6A 15,0 WH | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 15 m | white |
| 24441416 | ETHERLINE® LAN Cat.6A 20,0 WH | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 20 m | white |
| 24441417 | ETHERLINE® LAN Cat.6A 25,0 WH | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 25 m | white |
| 24441418 | ETHERLINE® LAN Cat.6A 30,0 WH | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 30 m | white |
| 24441419 | ETHERLINE® LAN Cat.6A 40,0 WH | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 40 m | white |
| 24441420 | ETHERLINE® LAN Cat.6A 50,0 WH | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 50 m | white |
| 24441421 | ETHERLINE® LAN Cat.6A 0,25 YE | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.25 m | yellow |
| 24441422 | ETHERLINE® LAN Cat.6A 0,5 YE | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 0.5 m | yellow |
| 24441423 | ETHERLINE® LAN Cat.6A 1,0 YE | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1 m | yellow |
| 24441424 | ETHERLINE® LAN Cat.6A 1,5 YE | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 1.5 m | yellow |
| 24441425 | ETHERLINE® LAN Cat.6A 2,0 YE | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 2 m | yellow |
| 24441426 | ETHERLINE® LAN Cat.6A 3,0 YE | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 3 m | yellow |
| 24441427 | ETHERLINE® LAN Cat.6A 5,0 YE | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 5 m | yellow |
| 24441428 | ETHERLINE® LAN Cat.6A 7,5 YE | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 7.5 m | yellow |
| 24441429 | ETHERLINE® LAN Cat.6A 10,0 YE | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 10 m | yellow |
| 24441430 | ETHERLINE® LAN Cat.6A 15,0 YE | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 15 m | yellow |
| 24441431 | ETHERLINE® LAN Cat.6A 20,0 YE | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 20 m | yellow |
| 24441432 | ETHERLINE® LAN Cat.6A 25,0 YE | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 25 m | yellow |
| 24441433 | ETHERLINE® LAN Cat.6A 30,0 YE | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 30 m | yellow |
| 24441434 | ETHERLINE® LAN Cat.6A 40,0 YE | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 40 m | yellow |
| 24441435 | ETHERLINE® LAN Cat.6A 50,0 YE | RJ45; Plug; Straight; Number of contacts: 8 | RJ45; Plug; Straight; Number of contacts: 8 | 50 m | yellow |

V1.1