


POF ADAPTER FSMA /4PC

Article No.: 29430099

Fiber optic coupling; Coupling; Straight; Simplex; Suitable fibre width: 1000; screw;

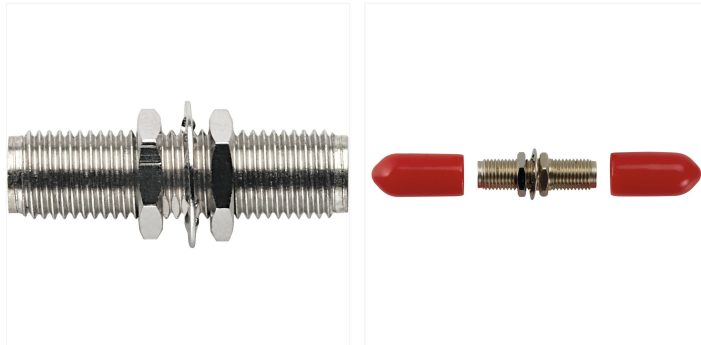

Details

Application

- Use at temperatures up to 40°C possible.

Notes

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Remarks

Technical Data

General information

Brand	HITRONIC®
Product type	Fiber optic coupling
Scope of delivery	4 couplings

Delivery Unit	4
Mounting method	screw

Electrical parameters

Product design

Direct assembly possible	Yes
Anti-kink sleeve	No
Dust protection cap	Yes
Diameter connector	0.25 in
Total length	0.925 in
Variant of connector	Simplex
Connector housing design	Straight
Connector type	Coupling
Type of plug connection	F-SMA
Flange available	No
Contact connection type	Screw connection
Reusable	Yes
Assembly type	Field Configurable
Type of coupling connection	F-SMA
Suitable fibre width	1000 µm
Suitable type of optical fibre	Simplex
Housing main material	Nickel silver
Guide sleeve material	Nickel silver
Dust protection cap color	red
Colour of dust protection cap RAL code	RAL 3000
Connector color	silver

Product features

Min. number of insertion cycles	500
Insertion loss	1 dB
Storage temperature max.	-55 °C

Storage temperature maximum	100 °C
Operating temperature max.	-40 °C
Operation temperature max.	85 °C
UV-resistant	No
Contact type application	Fiber optic cables Data / Signals
Vibration protection	No

Certifications and standards

POF adapter F-SMA

Article No.	Name	Scope of delivery
29430089	POF ADAPTER FSMA HEX /4PC	4 coupling
29430099	POF ADAPTER FSMA /4PC	4 coupling

V1.1