


**SKINDICHT® EKU PG 9/11**

**Article No.:** 51731000

Enlarger; Inner thread: PG 11; Outer thread: PG 9; Polyamide; light gray

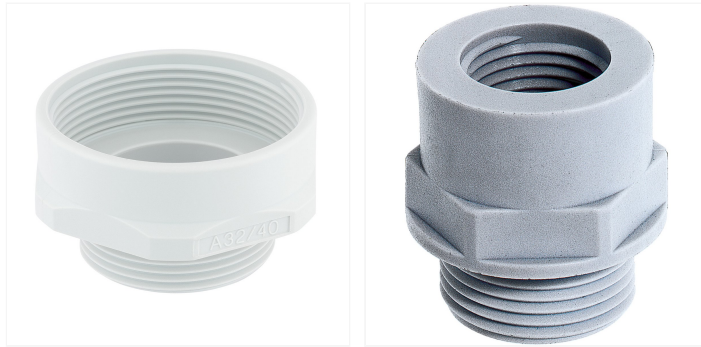

**CE**



**Details**

**Notes**

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

**Remarks**

**Technical Data**

**General information**

Brand	SKINDICHT®
Product type	Enlarger
Delivery with lock nut	No
Including o-ring	No

---

Type of packaging	Bag
Delivery Unit	100
Mounting method	in threaded borehole

---

**Electrical parameters****Product design**

Glass-fibre reinforced	Yes
With bending protection	No
Cable gland design	Straight
Inner thread	PG 11
Outer thread	PG 9
Inner diameter	0.394 in
Outer diameter	0.945 in
Total length	1.063 in
Clear width	0.394 in
Thread type	PG
Thread size	PG 9
Pitch of thread	1,41
Thread length	0.354 in
Spanner size 1	0.866 in
Hexagon corner dimensions	0.945 in
Wrench width	0.866 in
EMC shielding	No
Body material	Polyamide
Body material, short form	PA
Surface protection	Uncoated
Colour description	light gray
RAL color	RAL 7035

---

**Product features**

Suitable for EX-applications	No
------------------------------	----

---

---

Temperature (min.)	-40 °C
Max. temperatur	100 °C
Flame-retardant	No
UV-resistant	No
Chemical resistant	Yes
Acid-resistant	No
Halogenfree	Yes
Oil resistant	Yes

---

**Certifications and standards**

CE marking	Yes
UL recognized	No
UL listed	No
cUR recognized	No
cUL listed	No
CSA certified	No
VDE certified	No
GGVS certified	No
Tested for fire protection for railway vehicles	No
Ecolab certified	No
NSF certified	No
FDA certified	No
EHEDG certified	No

---

**SKINDICHT® EKU**

Article No.	Name	Outer thread	Inner thread	Colour description	Delivery Unit
51731000	SKINDICHT® EKU PG 9/11	PG 9	PG 11	light gray	100
51731010	SKINDICHT® EKU PG 11/13.5	PG 11	PG 13,5	light gray	50
51731020	SKINDICHT® EKU PG 13.5/16	PG 13,5	PG 16	light gray	50
51731030	SKINDICHT® EKU PG 16/21	PG 16	PG 21	light gray	25
51731040	SKINDICHT® EKU PG 21/29	PG 21	PG 29	light gray	25
52025200	SKINDICHT® EKU PG 7/9	PG 7	PG 9	light gray	50
52025210	SKINDICHT® EKU PG 29/36	PG 29	PG 36	light gray	25

V1.1