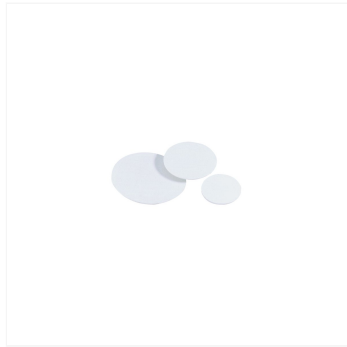


**SKINDICHT® STK PG 11****Article No.:** 52020830

Sealing insert; Polyvinylchloride; white

**Details****Notes**

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

**Remarks**

Delivery will be made in the largest possible packing unit (bulk goods), minimum order quantity is one PU.

**Technical Data****General information**

Brand	SKINDICHT®
Product type	Sealing insert

---

Type of packaging	Bag
Delivery Unit	250

---

**Electrical parameters****Product design**

Glass-fibre reinforced	No
Outer diameter	0.669 in
Overall height	0.02 in
Material sealing	Polyvinylchloride
Material sealing shortname	PVC
Colour description	white

---

**Product features**

Suitable for EX-applications	No
Temperature (min.)	-20 °C
Max. temperatur	80 °C
Flame-retardant	No
UV-resistant	No
Halogenfree	No
Oil resistant	Yes

---

**Certifications and standards**

CE marking	No
Ecolab certified	No

---

---

**SKINDICHT® STK**

Article No.	Name	Outer diameter	Delivery Unit
52020818	SKINDICHT® STK PG 7	0.433 in	500
52020820	SKINDICHT® STK PG 9	0.531 in	500
52020830	SKINDICHT® STK PG 11	0.669 in	250
52020840	SKINDICHT® STK PG 13.5	0.728 in	250
52020850	SKINDICHT® STK PG 16	0.807 in	250
52020860	SKINDICHT® STK PG 21	1.024 in	250
52020870	SKINDICHT® STK PG 29	1.378 in	100
52020880	SKINDICHT® STK PG 36	1.772 in	100
52020890	SKINDICHT® STK PG 42	2.047 in	50
52020900	SKINDICHT® STK PG 48	2.244 in	50

V1.1