


SILVYN® HIPROJACKET NW 6 15M

Article No.: 52021385

Simple protective cable conduit; Inner diameter: 0.236in; Outer diameter: 0.433in; Nominal size: 6; Silicone; Halogen-free; UV-resistant

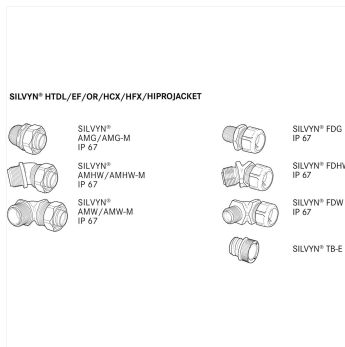

Details

Notes

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Remarks

 Technical Data

General information

Brand	SILVYN®
Product type	Simple protective cable conduit
Industry segment	Healthcare & Pharma Packaging Process Industry Rolling Stock

Electrical parameters
Product design

With bending protection	No
Bending protection fixed installation	No
Flexibly installed bending protection	No
Slotted	No
Resistance against hot swarf	Yes
Inner diameter	0.236 in
Outer diameter	0.433 in
Total length	590.551 in
Nominal size	6 "
Lockable (two-part)	No
Material braiding	Glass fiber
Body material	Silicone
Material conduit	Silicone
Conduit surface externally smooth	Yes
Smooth inner conduit surface	No
Colour description	red

Product features

For permanent bending	No
Suitable for EX-applications	No

Short term temperature max.	1,640 °C
Flame-retardant	Yes
Flame retardance according to	UL VW-1
UV-resistant	Yes
Halogenfree	Yes
Oil resistant	Yes
Strain relief	No

Certifications and standards

CE marking	No
EAC certified	Not required
EAC certification number	Отказное письмо № 254-ОП/03-2021
UL recognized	No
UL listed	No
cUR recognized	No
cUL listed	No
CSA certified	No
VDE certified	No
GGVS certified	No
DNV-certified	No
Tested for fire protection for railway vehicles	Yes
Fire protection for railway vehicles hazard level	EN 45545-2 HL1 EN 45545-2 HL2 EN 45545-2 HL3
Ecolab certified	No
NSF certified	No
FDA certified	No
EHEDG certified	No

SILVYN® HIPROJACKET

Article No.	Name	Inner diameter	Outer diameter	Nominal size	Total length	Delivery Unit
52021385	SILVYN® HIPROJACKET NW 6 15M	0.236 in	0.433 in	6 "	590.551 in	
61713000	SILVYN® HIPROJACKET NW 25 15M	0.984 in	1.22 in	25 "	590.551 in	
61713003	SILVYN® HIPROJACKET NW 10 15M	0.394 in	0.591 in	10 "	590.551 in	
61713005	SILVYN® HIPROJACKET NW 13 15M	0.512 in	0.709 in	13 "	590.551 in	
61713007	SILVYN® HIPROJACKET NW 16 15M	0.63 in	0.866 in	16 "	590.551 in	
61713010	SILVYN® HIPROJACKET NW 19 15M	0.748 in	0.984 in	19 "	590.551 in	15
61713011	SILVYN® HIPROJACKET NW 22 15M	0.866 in	1.102 in	22 "	590.551 in	
61713014	SILVYN® HIPROJACKET NW 29 15M	1.142 in	1.378 in	29 "	590.551 in	
61713015	SILVYN® HIPROJACKET NW 32 15M	1.26 in	1.496 in	32 "	590.551 in	
61713016	SILVYN® HIPROJACKET NW 35 15M	1.378 in	1.614 in	35 "	590.551 in	
61713017	SILVYN® HIPROJACKET NW 38 15M	1.496 in	1.732 in	38 "	590.551 in	
61713018	SILVYN® HIPROJACKET NW 41 15M	1.614 in	1.85 in	41 "	590.551 in	

V1.1