


ROUND CABLE WEDGE CLAMPS RKK 05

Article No.: 52026030

Cable wedge clamp; Cable diameter: 0.748in - 0.945in; Number of cables: 1; Polyamide

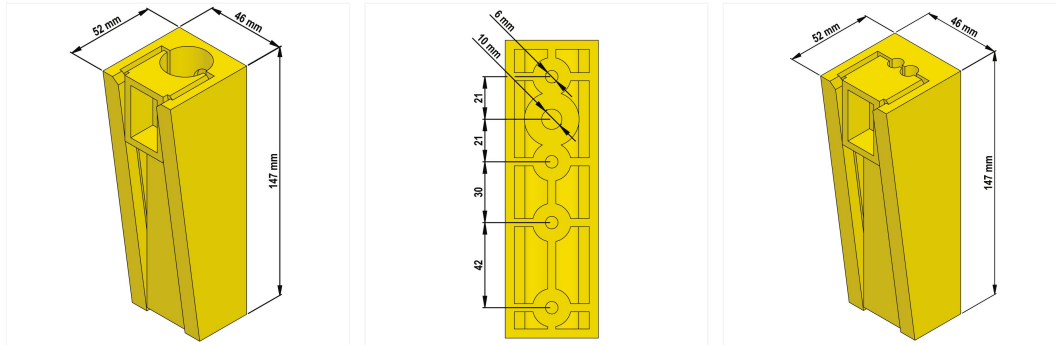

Details

Notes

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Trade product, not a LAPP product.

Remarks

Trade product, not a LAPP product.

Technical Data

General information

| | |
|---------------|-------------------|
| Product type | Cable wedge clamp |
| Delivery Unit | 1 |

Electrical parameters**Product design**

| | |
|-------------------------------|-----------|
| number of cables | 1 |
| Total length | 5.827 in |
| Overall width | 1.811 in |
| Overall height | 2.047 in |
| For min. cable outer diameter | 0.748 in |
| For max. cable outer diameter | 0.945 in |
| Material | Polyamide |
| Colour description | orange |

Product features

| | |
|-----------------------|-------|
| Halogenfree | Yes |
| Clamping force (max.) | 343 N |

Certifications and standards

RKK Round cable wedge clamps

| Article No. | Name | For min. cable outer diameter | For max. cable outer diameter | number of cables | Delivery Unit |
|-------------|---------------------------------|-------------------------------|-------------------------------|------------------|---------------|
| 52026020 | ROUND CABLE WEDGE CLAMPS RKK 01 | 0.276 in | 0.433 in | 2 | 1 |
| 52026022 | ROUND CABLE WEDGE CLAMPS RKK 06 | 0.453 in | 0.551 in | 1 | 1 |
| 52026024 | ROUND CABLE WEDGE CLAMPS RKK 02 | 0.709 in | 0.827 in | 1 | 1 |
| 52026030 | ROUND CABLE WEDGE CLAMPS RKK 05 | 0.748 in | 0.945 in | 1 | 1 |

V1.1