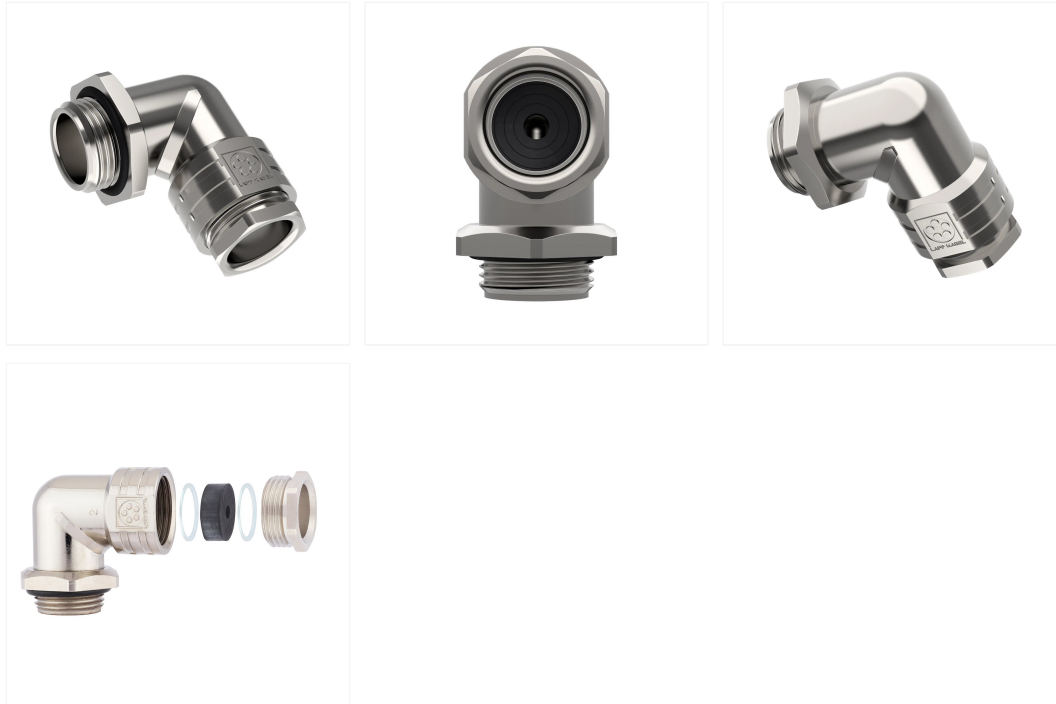


**SKINDICHT® RWV-M 16X1.5****Article No.:** 52107810

Angled cable gland; M 16; Clamping range (min./max.): 0.118 - 0.354 in; Zinc alloy Nickel-plated; 90° angle; IP 55

**CE****Details****Application**

- Machine and equipment manufacturing
- Plant engineering

**Notes**

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

### Remarks

### Technical Data

#### General information

Brand	SKINDICHT®
Product type	Angled cable gland
Scope of delivery	including O-ring
Delivery with lock nut	No
Including o-ring	Yes
Type of packaging	Bag
Delivery Unit	25
Mounting method	in threaded borehole

#### Electrical parameters

#### Product design

For armored cables	No
Glass-fibre reinforced	No
Number of cable entries	1 pc.
With bending protection	No
Cable gland design	90° angle
Clear width	0.472 in
Thread type	Metric
Thread size	M 16
Pitch of thread	1,5
Thread length	0.256 in
Thread standard	DIN EN 60423
Spanner size 1	0.709 in
Wrench size 2	0.63 in
Wrench width	0.866 in
Clamping range min.	0.118 in

Clamping range max.	0.354 in
EMC shielding	No
Thread-side sealing element	O-ring
Cable-side sealing element	Incized sealing ring
Material o-ring	Acrylonitrile butadiene rubber
O-ring material, short form	NBR
Material sealing	Chloroprene rubber
Body material	Zinc alloy
Colour description	metal

### Product features

IP protection rating	IP 55
Suitable for EX-applications	No
Temperature (min.)	-20 °C
Max. temperatur	80 °C
Flame-retardant	No
UV-resistant	Yes
Halogenfree	No
Oil resistant	Yes
Impact proof	Yes
Vibration protection	No
Strain relief	Yes

### Certifications and standards

CE marking	Yes
UL recognized	No
UL listed	No
cUR recognized	No
cUL listed	No
CSA certified	No
VDE certified	No
GGVS certified	No
DNV-certified	No

---

Ecolab certified	No
NSF certified	No
EHEDG certified	No

---

**SKINDICHT® RWV-M**

Article No.	Name	Thread size	Thread length	Clamping range min.	Clamping range max.	Spanner size 1	Delivery Unit
52107800	SKINDICHT® RWV-M 12X1.5	M 12	0.256 in		0.197 in	0.551 in	25
52107810	SKINDICHT® RWV-M 16X1.5	M 16	0.256 in	0.118 in	0.354 in	0.709 in	25
52107820	SKINDICHT® RWV-M 20X1.5	M 20	0.295 in	0.157 in	0.512 in	0.866 in	25
52107830	SKINDICHT® RWV-M 25X1.5	M 25	0.335 in	0.335 in	0.689 in	1.063 in	10
52107840	SKINDICHT® RWV-M 32X1.5	M 32	0.335 in	0.63 in	0.984 in	1.339 in	10
52107850	SKINDICHT® RWV-M 40X1.5	M 40	0.413 in	0.906 in	1.26 in	1.654 in	5

V1.1