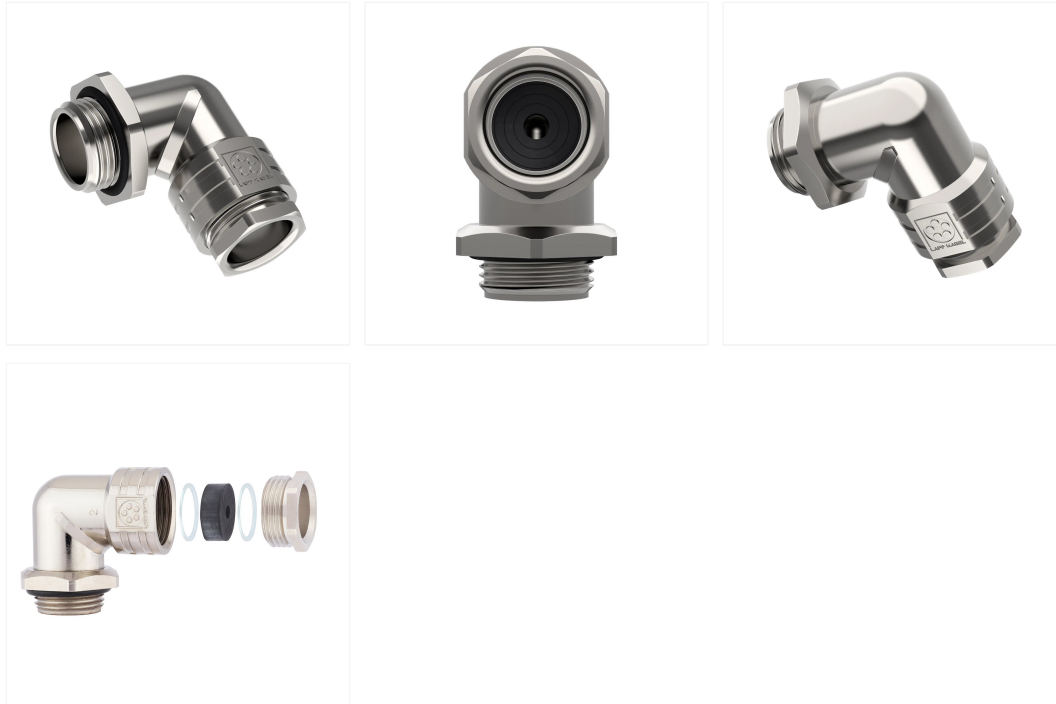


SKINDICHT® RWV-M 25X1.5**Article No.:** 52107830

Angled cable gland; M 25; Clamping range (min./max.): 0.335 - 0.689 in; Zinc alloy Nickel-plated; 90° angle; IP 55

**CE****Details****Application**

- Machine and equipment manufacturing
- Plant engineering

Notes

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Remarks

Technical Data

General information

| | |
|------------------------|----------------------|
| Brand | SKINDICHT® |
| Product type | Angled cable gland |
| Scope of delivery | including O-ring |
| Delivery with lock nut | No |
| Including o-ring | Yes |
| Type of packaging | Bag |
| Delivery Unit | 10 |
| Mounting method | in threaded borehole |

Electrical parameters

Product design

| | |
|-------------------------|--------------|
| For armored cables | No |
| Glass-fibre reinforced | No |
| Number of cable entries | 1 pc. |
| With bending protection | No |
| Cable gland design | 90° angle |
| Clear width | 0.787 in |
| Thread type | Metric |
| Thread size | M 25 |
| Pitch of thread | 1,5 |
| Thread length | 0.335 in |
| Thread standard | DIN EN 60423 |
| Spanner size 1 | 1.063 in |
| Wrench size 2 | 0.984 in |
| Wrench width | 1.26 in |
| Clamping range min. | 0.335 in |

| | |
|-----------------------------|--------------------------------|
| Clamping range max. | 0.689 in |
| EMC shielding | No |
| Thread-side sealing element | O-ring |
| Cable-side sealing element | Incized sealing ring |
| Material o-ring | Acrylonitrile butadiene rubber |
| O-ring material, short form | NBR |
| Material sealing | Chloroprene rubber |
| Body material | Zinc alloy |
| Colour description | metal |

Product features

| | |
|------------------------------|--------|
| IP protection rating | IP 55 |
| Suitable for EX-applications | No |
| Temperature (min.) | -20 °C |
| Max. temperatur | 80 °C |
| Flame-retardant | No |
| UV-resistant | Yes |
| Halogenfree | No |
| Oil resistant | Yes |
| Impact proof | Yes |
| Vibration protection | No |
| Strain relief | Yes |

Certifications and standards

| | |
|----------------|-----|
| CE marking | Yes |
| UL recognized | No |
| UL listed | No |
| cUR recognized | No |
| cUL listed | No |
| CSA certified | No |
| VDE certified | No |
| GGVS certified | No |
| DNV-certified | No |

| | |
|------------------|----|
| Ecolab certified | No |
| NSF certified | No |
| EHEDG certified | No |

SKINDICHT® RWV-M

| Article No. | Name | Thread size | Thread length | Clamping range min. | Clamping range max. | Spanner size 1 | Delivery Unit |
|-------------|-------------------------|-------------|---------------|---------------------|---------------------|----------------|---------------|
| 52107800 | SKINDICHT® RWV-M 12X1.5 | M 12 | 0.256 in | | 0.197 in | 0.551 in | 25 |
| 52107810 | SKINDICHT® RWV-M 16X1.5 | M 16 | 0.256 in | 0.118 in | 0.354 in | 0.709 in | 25 |
| 52107820 | SKINDICHT® RWV-M 20X1.5 | M 20 | 0.295 in | 0.157 in | 0.512 in | 0.866 in | 25 |
| 52107830 | SKINDICHT® RWV-M 25X1.5 | M 25 | 0.335 in | 0.335 in | 0.689 in | 1.063 in | 10 |
| 52107840 | SKINDICHT® RWV-M 32X1.5 | M 32 | 0.335 in | 0.63 in | 0.984 in | 1.339 in | 10 |
| 52107850 | SKINDICHT® RWV-M 40X1.5 | M 40 | 0.413 in | 0.906 in | 1.26 in | 1.654 in | 5 |

V1.1