


SKINTOP® BS NPT 3/8IN RAL 9005 BK
Article No.: 53016810

Cable gland with bending protection; NPT 3/8"; Clamping range (min./max.): 0.138 - 0.315 in; Spanner size 1: 0.748; black; Polyamide Uncoated; UV-resistant; IP 68 - 5 g/cm² (30 min)

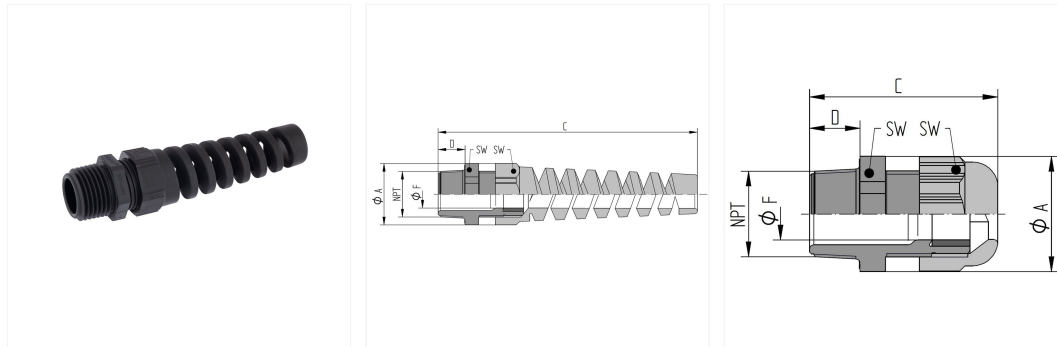

Details

Application

- Machine and equipment manufacturing

Notes

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Remarks

Technical Data

General information

Brand	SKINTOP®
Product type	Cable gland with bending protection
Delivery with lock nut	No
Including o-ring	No
Type of packaging	Bag
Delivery Unit	100

Electrical parameters
Product design

For armored cables	No
Glass-fibre reinforced	No
Number of cable entries	1 pc.
Bending protection	Spiral
With bending protection	Yes
Cable gland design	Straight
Total length	3.228 in
Clear width	0.315 in
Thread type	NPT
Thread size	NPT 3/8"
Pitch of thread	1,41
Thread length	0.591 in
Spanner size 1	0.748 in
Wrench size 2	0.748 in
Hexagon corner dimensions	0.831 in
Clamping range min.	0.138 in
Clamping range max.	0.315 in
EMC shielding	No
Seal type	Conduit Sealing Ring
Cable-side sealing element	Conduit Sealing Ring
Material sealing	Chloroprene rubber
Body material	Polyamide

Body material, short form	PA
Bending protection material	Polyamide
Surface protection	Uncoated
Colour description	black
RAL color	RAL 9005

Product features

IP protection rating	IP 68 - 5 g/cm ² (30 min)
NEMA classification type	Type 1 Type 12
Suitable for EX-applications	No
Temperature (min.)	-20 °C
Max. temperatur	100 °C
Flame-retardant	Yes
Flame retardance according to	UL 94 V-2
UV-resistant	Yes
Chemical resistant	Yes
Acid-resistant	No
Halogenfree	No
Oil resistant	Yes
Impact proof	Yes
Vibration protection	Yes
Strain relief	Yes

Certifications and standards

CE marking	Yes
UL recognized	Yes
UL AWM certification	according to UL 514B (CCN: QBPZ2 / e-file number: E79903)
UL listed	No
cUR recognized	Yes
cUR certification	according to CSA C22.2 No. 18.3 (CCN: QBPZ8 / e-file number: E79903)

cUL listed	No
CSA certified	No
VDE certified	No
For Ex zone gas	without
For Ex-zone dust	without
GGVS certified	No
DNV-certified	No
Tested for fire protection for railway vehicles	No
Ecolab certified	No
NSF certified	No
FDA certified	No
EHEDG certified	No

SKINTOP® BS NPT

Article No.	Name	Thread size	Thread length	Clamping range min.	Clamping range max.	Spanner size 1	Colour description	Delivery Unit
53016610	SKINTOP® BS NPT 3/8IN RAL 7001 SGY	NPT 3/8"	0.591 in	0.138 in	0.315 in	0.748 in	silver gray	100
53016630	SKINTOP® BS NPT 1/2IN RAL 7001 SGY	NPT 1/2"	0.591 in	0.197 in	0.472 in	0.945 in	silver gray	50
53016650	SKINTOP® BS NPT 3/4IN RAL 7001 SGY	NPT 3/4"	0.591 in	0.512 in	0.709 in	1.299 in	silver gray	25
53016810	SKINTOP® BS NPT 3/8IN RAL 9005 BK	NPT 3/8"	0.591 in	0.138 in	0.315 in	0.748 in	black	100
53016830	SKINTOP® BS NPT 1/2IN RAL 9005 BK	NPT 1/2"	0.591 in	0.197 in	0.472 in	0.945 in	black	50
53016850	SKINTOP® BS NPT 3/4IN RAL 9005 BK	NPT 3/4"	0.591 in	0.512 in	0.709 in	1.299 in	black	25

V1.1