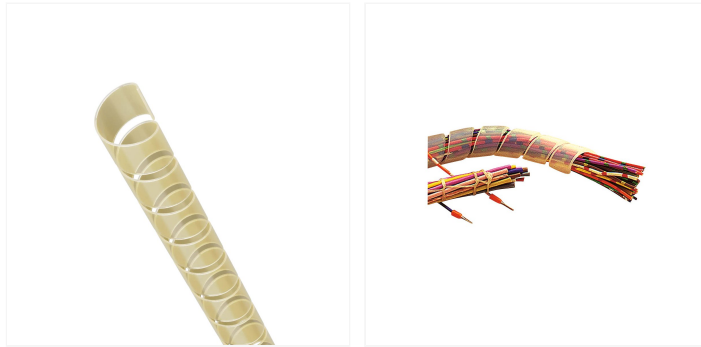


PLASTIC COIL KW 2 NR**Article No.:** 61600010

Cable bundle conduit; 0.059in - 0.276in; natural; Polyethylene

**Details****Notes**

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Trade product, not a LAPP product.

Remarks

Trade product, not a LAPP product.

Technical Data**General information**

Product type	Cable bundle conduit
Delivery Unit	50

Electrical parameters**Product design**

Inner diameter	0.059 in
Outer diameter	0.118 in
Total length	1,968.504 in
Wall thickness	0.03 in
for bundling diameter (min.)	0.059 in
for bundling diameter (max.)	0.276 in
Material	Polyethylene
Colour description	natural

Product features

Flame-retardant	No
UV-resistant	No
Halogenfree	No
Elongation at break	550 %

Certifications and standards

KW plastic coil

Article No.	Name	for bundling diameter (min.)	for bundling diameter (max.)	Colour description	Material	Total length
61600010	PLASTIC COIL KW 2 NR	0.059 in	0.276 in	natural	Polyethylene	1,968.504 in
61600015	PLASTIC COIL KW 2 BK	0.079 in	0.276 in	black	Polyamide	1,968.504 in
61600040	PLASTIC COIL KW5 NR	0.197 in	0.787 in	natural	Polyethylene	1,181.102 in
61600045	PLASTIC COIL KW5 BK	0.197 in	0.787 in	black	Polyamide	984.252 in
61600050	PLASTIC COIL KW5 YE	0.197 in	0.787 in	yellow	Polyethylene	984.252 in
61600070	PLASTIC COIL KW10 NR	0.394 in	1.575 in	natural	Polyethylene	1,181.102 in
61600080	PLASTIC COIL KW10 YE	0.394 in	1.575 in	yellow	Polyethylene	984.252 in
61722840	PLASTIC COIL KW10 BK	0.394 in	1.575 in	black	Polyamide	984.252 in

V1.1