


**SILVYN® SI 9X12 SGY**

**Article No.:** 61713240

Simple protective cable conduit; Inner diameter: 0.354in; Outer diameter: 0.472in; Polyvinylchloride;

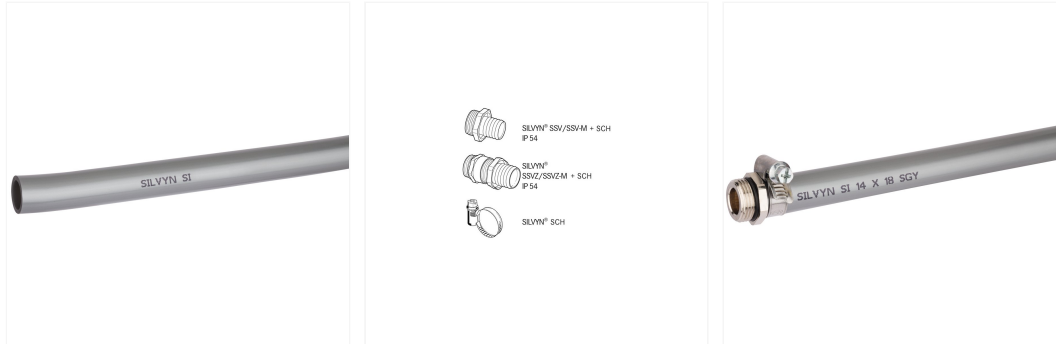

**Details**

**Notes**

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

**Remarks**

**Technical Data**

**General information**

Brand	SILVYN®
Product type	Simple protective cable conduit
Type of packaging	Ring
Delivery Unit	50

**Electrical parameters****Product design**

With bending protection	No
Bending protection fixed installation	No
Flexibly installed bending protection	No
Slotted	No
Resistance against hot swarf	No
Inner diameter	0.354 in
Outer diameter	0.472 in
Total length	1.969 in
EMC shielding	No
jacket material	no jacket
Body material	Polyvinylchloride
Body material, short form	PVC
Material conduit	Polyvinylchloride
Conduit material, short form	PVC
Coil material	without helix
Conduit surface externally smooth	Yes
Smooth inner conduit surface	Yes
Colour description	silver gray
RAL color	RAL 7001

**Product features**

For permanent bending	No
IP protection rating	IP 68
Suitable for EX-applications	No
Flexibility	Flexible
Flame-retardant	Yes
Flame retardance according to	VDE 0472-804
UV-resistant	No

---

Chemical resistant	Yes
Acid-resistant	No
Halogenfree	No
Oil resistant	Yes
Impact proof	No
Shore hardness	75 shore
Strain relief	No

**Certifications and standards**

CE marking	Yes
EAC certified	Not required
EAC certification number	Отказное письмо № 505
UL recognized	No
UL listed	No
cUR recognized	No
cUL listed	No
CSA certified	No
VDE certified	No
Product standard DIN / EN	EN 61386-23
GGVS certified	No
DNV-certified	No
Tested for fire protection for railway vehicles	No
Ecolab certified	No
NSF certified	No
FDA certified	No
EHEDG certified	No

**SILVYN® SI**

Article No.	Name	Inner diameter	Outer diameter	Total length	Delivery Unit
61713210	SILVYN® SI 7X9 SGY	0.276 in	0.354 in	1.969 in	50
61713240	SILVYN® SI 9X12 SGY	0.354 in	0.472 in	1.969 in	50
61713270	SILVYN® SI 11X14 SGY	0.433 in	0.551 in	1.969 in	50
61713300	SILVYN® SI 13X16 SGY	0.512 in	0.63 in	1.969 in	50
61713330	SILVYN® SI 14X18 SGY	0.551 in	0.709 in	1.969 in	50
61713360	SILVYN® SI 18X22 SGY	0.709 in	0.866 in	1.969 in	50
61713390	SILVYN® SI 23X28 SGY	0.906 in	1.102 in	1.969 in	50
61713420	SILVYN® SI 32X38 SGY	1.26 in	1.496 in	1.969 in	50

V1.1