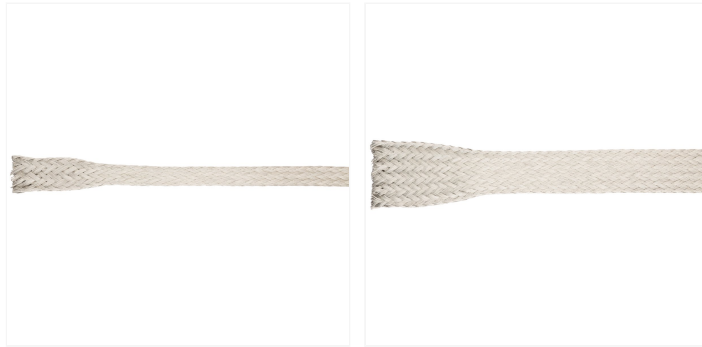


COPPER SCREEN BRAIDING CU 410**Article No.:** 61721380

Braided shield; Cable diameter: 0.157in - 0.394in; Copper Tin-plated

**Details****Notes**

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Trade product, not a LAPP product.

Remarks

A VPE consists of two sections

Trade product, not a LAPP product.

Technical Data**General information**

Product type

Braided shield

| | |
|------------------|--|
| Copper index | 278.19 lb/10000 ft |
| Delivery Unit | 100 |
| Industry segment | Energy Heating, Ventilation, Air Conditioning & Refrigeration Packaging |

Electrical parameters

Product design

| | |
|---|--------------|
| Wire count | 528 |
| Degree of coverage (at maximum opening) | 85 % |
| Total length | 3,937.008 in |
| EMC shielding | Yes |
| For min. cable outer diameter | 0.157 in |
| For max. cable outer diameter | 0.394 in |
| Material | Copper |
| Surface protection | Tin-plated |

Product features

| | |
|-----------------------------|--------|
| Short term temperature max. | 120 °C |
|-----------------------------|--------|

Certifications and standards

| | |
|---------------|----|
| UL recognized | No |
| UL listed | No |
| VDE certified | No |

Copper braid

| Article No. | Name | For min. cable outer diameter | For max. cable outer diameter | Delivery Unit |
|-------------|--------------------------------|-------------------------------|-------------------------------|---------------|
| 61721370 | COPPER SCREEN BRAIDING CU 14 | 0.039 in | 0.157 in | 100 |
| 61721380 | COPPER SCREEN BRAIDING CU 410 | 0.157 in | 0.394 in | 100 |
| 61721390 | COPPER SCREEN BRAIDING CU 1020 | 0.394 in | 0.787 in | 100 |
| 61721395 | COPPER SCREEN BRAIDING CU 2050 | 0.787 in | 1.969 in | 100 |

V1.1