


TIE SCREW SOCKET TC 826

Article No.: 61724810

Cable tie mount; for cable tie width: 0.189in; natural; Polyamide; Halogen-free;

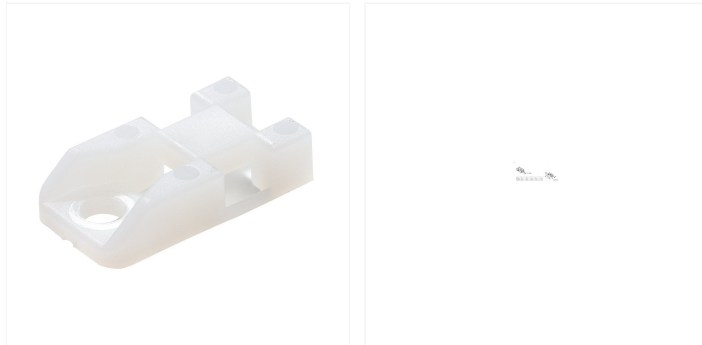

Details

Notes

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Trade product, not a LAPP product.

Remarks

Trade product, not a LAPP product.

Technical Data

General information

Product type	Cable tie mount
Scope of delivery	without screws

Delivery Unit	1,000
pieces per PU	1,000 pc.

Electrical parameters**Product design**

Total length	0.945 in
Overall width	0.512 in
Overall height	0.224 in
Bore diameter	0.165 in
Material	Polyamide
Colour description	natural
for cable tie width	0.189 in

Product features

Flame-retardant	No
UV-resistant	No
Halogenfree	Yes
Oil resistant	Yes

Certifications and standards

UL recognized	No
UL listed	No
cUR recognized	No
cUL listed	No
CSA certified	No
VDE certified	No
DNV-certified	No
Ecolab certified	No

Tie screw socket

Article No.	Name	for cable tie width	Total length	Overall width	pieces per PU
61724810	TIE SCREW SOCKET TC 826	0.189 in	0.945 in	0.512 in	1,000 pc.
61724820	TIE SCREW SOCKET TC 828-TB	0.189 in	0.906 in	0.394 in	1,000 pc.

V1.1