


SILVYN® SEALING WASHER M20

Article No.: 61809410

Flat sealing ring; Inner diameter: 0.787in; Outer diameter: 1.063in; Polyester; blue

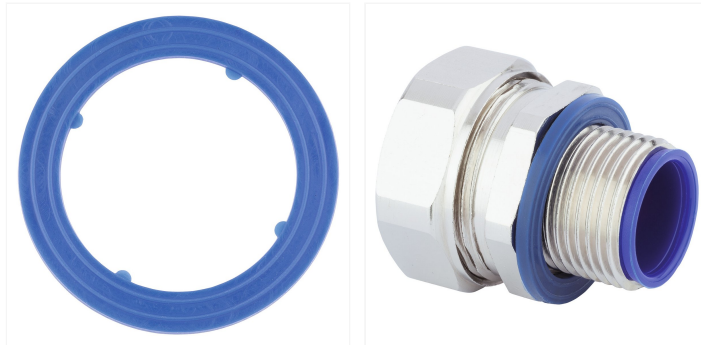

Details

Notes

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Remarks

Technical Data

General information

Brand	SILVYN®
Product type	Flat sealing ring
Type of packaging	Bag
Delivery Unit	10

Electrical parameters**Product design**

Divisible conduit gland	No
Inner diameter	0.787 in
Outer diameter	1.063 in
Clear width	0.787 in
Material sealing	Polyester
Colour description	blue

Product features

Flame-retardant	Yes
UV-resistant	Yes
Chemical resistant	Yes
Acid-resistant	No
Halogenfree	Yes
Oil resistant	Yes
Vibration protection	Yes

Certifications and standards

CE marking	No
DNV-certified	No
EHEDG certified	No

SILVYN® SEALING WASHER

Article No.	Name	Inner diameter	Outer diameter	Delivery Unit
61809400	SILVYN® SEALING WASHER M16	0.63 in	0.945 in	10
61809410	SILVYN® SEALING WASHER M20	0.787 in	1.063 in	10
61809420	SILVYN® SEALING WASHER M25	0.984 in	1.339 in	10

V1.1