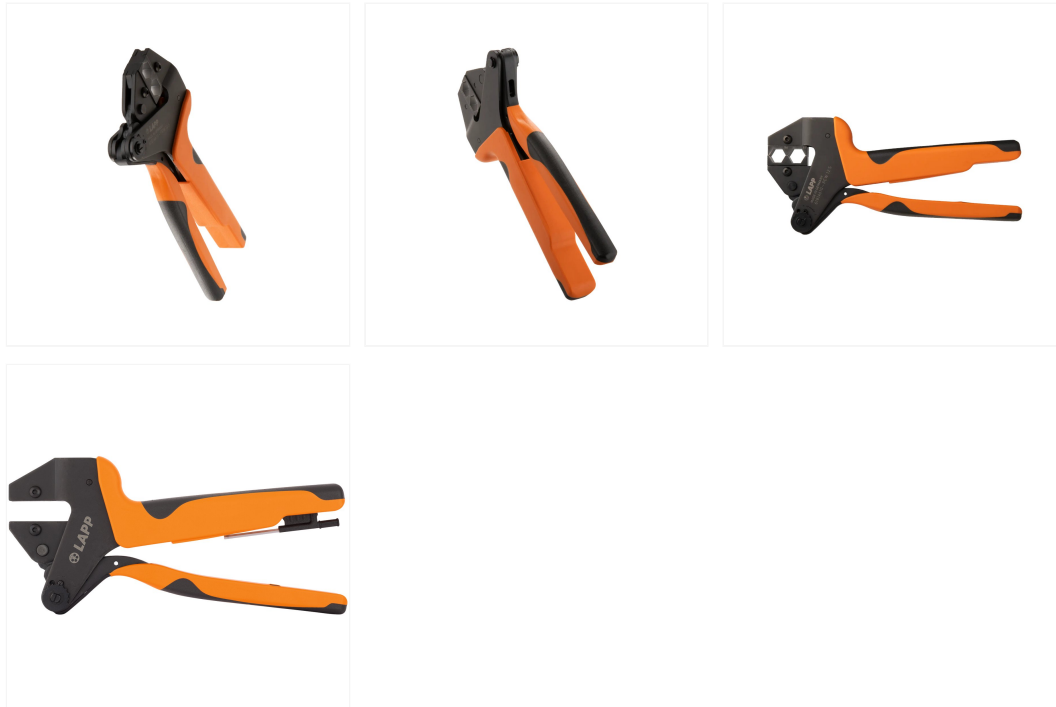


CRIMPING PLIERS PEW 12**Article No.:** 61813807

Modular crimping system;

**Details****Benefits**

- Suitable for almost all crimp connectors with a cross-section of 0.08 - 95.00 mm².
- Allows one- and two-handed operation.
- With rotary knob for individual adjustment of the crimp strength.
- The case is used for practical storage of crimping pliers and crimping dies.
- The table holder is used to secure the crimping pliers at the workstation. This makes crimping processes more efficient and less laborious.
- Separately available crimping inserts allow flexibility in the choice of the crimping profile.

Application

- For making a secure crimp connection.
- For use with turned and stamped contacts, with end sleeves and crimpable data connectors.

- For use with the "PEW 12 inserts" crimping inserts.

Notes

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Trade product, not a LAPP product.

Remarks

Trade product, not a LAPP product.

Technical Data

General information

| | |
|-------------------|--------------------------|
| Product type | Modular crimping system |
| Scope of delivery | without crimping inserts |
| Delivery Unit | 1 |

Electrical parameters

Product design

| | |
|--------------------|----------|
| Total length | 7.874 in |
| Overall width | 3.74 in |
| Overall height | 0.906 in |
| Material | Steel |
| Colour description | orange |

Product features

| | |
|---------------------|-----|
| corrosion resistant | Yes |
|---------------------|-----|

Certifications and standards

| | |
|---------------|----|
| CE marking | No |
| VDE certified | No |
| TÜV certified | No |

PEW 12 universal tool

| Article No. | Name | For cross-section (min.) | For cross-section (max.) | Crimping profile |
|-------------|-----------------------------|--------------------------|--------------------------|------------------|
| 61813807 | CRIMPING PLIERS PEW 12 | | | |
| 61813819 | CRIMPING PLIERS PEW 12 CASE | | | |
| 61813830 | DESK-HOLDER PEW12 | | | |
| 61814610 | CRIMPING PLIERS PEW 12S | | | |

V1.1