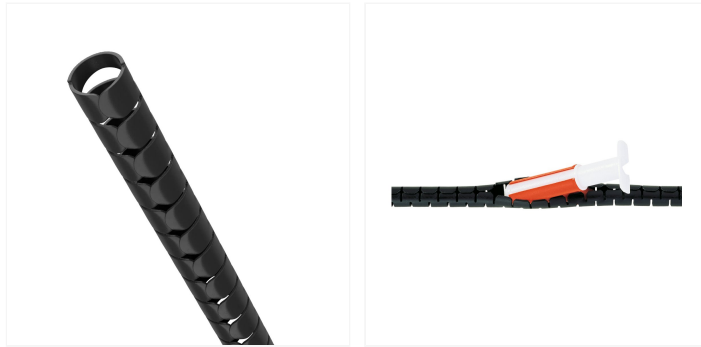


**CABLE EATER SHR-08-PPB BK****Article No.:** 61830300

Cable bundle conduit; 0.236in - 0.354in; black

**Details****Notes**

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Trade product, not a LAPP product.

**Remarks**

Trade product, not a LAPP product.

**Technical Data****General information**

Product type	Cable bundle conduit
Type of packaging	Pulley
Delivery Unit	100

**Electrical parameters****Product design**

Inner diameter	0.315 in
Total length	3,937.008 in
Wall thickness	0.031 in
for bundling diameter (min.)	0.236 in
for bundling diameter (max.)	0.354 in
Material	Polypropylene
Colour description	black

**Product features**

Flame-retardant	Yes
Flame retardance according to	UL 94 HB
Halogenfree	Yes
Oil resistant	Yes

**Certifications and standards**

**Cable-Eater bunched cable conduit**

Article No.	Name	for bundling diameter (min.)	for bundling diameter (max.)	Colour description	Total length
61830300	CABLE EATER SHR-08-PPB BK	0.236 in	0.354 in	black	3,937.008 in
61830302	CABLE EATER SHR-08-PPBW WH	0.236 in	0.354 in	white	3,937.008 in
61830310	CABLE EATER SHR-15-PPB BK	0.394 in	0.63 in	black	1,968.504 in
61830312	CABLE EATER SHR-15-PPBW WH	0.394 in	0.63 in	white	1,968.504 in
61830320	CABLE EATER SHR-20-PPB BK	0.669 in	0.906 in	black	1,181.102 in
61830322	CABLE EATER SHR-20-PPBW WH	0.669 in	0.906 in	white	1,181.102 in
61830330	CABLE EATER SHR-25-PPB BK	0.827 in	0.984 in	black	787.402 in
61830332	CABLE EATER SHR-25-PPBW WH	0.827 in	0.984 in	white	787.402 in
61830335	CABLE EATER SHR-32-PPB BK	1.142 in	1.26 in	black	590.551 in

V1.1