


CABLE EATER SHR-25-PPB BK

Article No.: 61830330

Cable bundle conduit; 0.827in - 0.984in; black

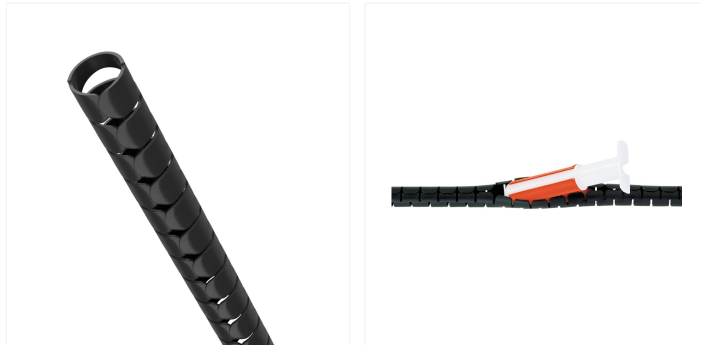

Details

Notes

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

Trade product, not a LAPP product.

Remarks

Trade product, not a LAPP product.

Technical Data

General information

Product type	Cable bundle conduit
Type of packaging	Pulley
Delivery Unit	20

Electrical parameters**Product design**

Inner diameter	0.984 in
Total length	787.402 in
Wall thickness	0.039 in
for bundling diameter (min.)	0.827 in
for bundling diameter (max.)	0.984 in
Material	Polypropylene
Colour description	black

Product features

Flame-retardant	Yes
Flame retardance according to	UL 94 HB
Halogenfree	Yes
Oil resistant	Yes

Certifications and standards

Cable-Eater bunched cable conduit

Article No.	Name	for bundling diameter (min.)	for bundling diameter (max.)	Colour description	Total length
61830300	CABLE EATER SHR-08-PPB BK	0.236 in	0.354 in	black	3,937.008 in
61830302	CABLE EATER SHR-08-PPBW WH	0.236 in	0.354 in	white	3,937.008 in
61830310	CABLE EATER SHR-15-PPB BK	0.394 in	0.63 in	black	1,968.504 in
61830312	CABLE EATER SHR-15-PPBW WH	0.394 in	0.63 in	white	1,968.504 in
61830320	CABLE EATER SHR-20-PPB BK	0.669 in	0.906 in	black	1,181.102 in
61830322	CABLE EATER SHR-20-PPBW WH	0.669 in	0.906 in	white	1,181.102 in
61830330	CABLE EATER SHR-25-PPB BK	0.827 in	0.984 in	black	787.402 in
61830332	CABLE EATER SHR-25-PPBW WH	0.827 in	0.984 in	white	787.402 in
61830335	CABLE EATER SHR-32-PPB BK	1.142 in	1.26 in	black	590.551 in

V1.1