


## Flexiprint LF1 0.75-1.5 YE

**Article No.:** 83254430

Laser printing label; For cross-section (min./max.): 0.75mm<sup>2</sup> - 1.5mm<sup>2</sup>; width printable area: 0.441in; Number of characters: 7; yellow; Halogen-free

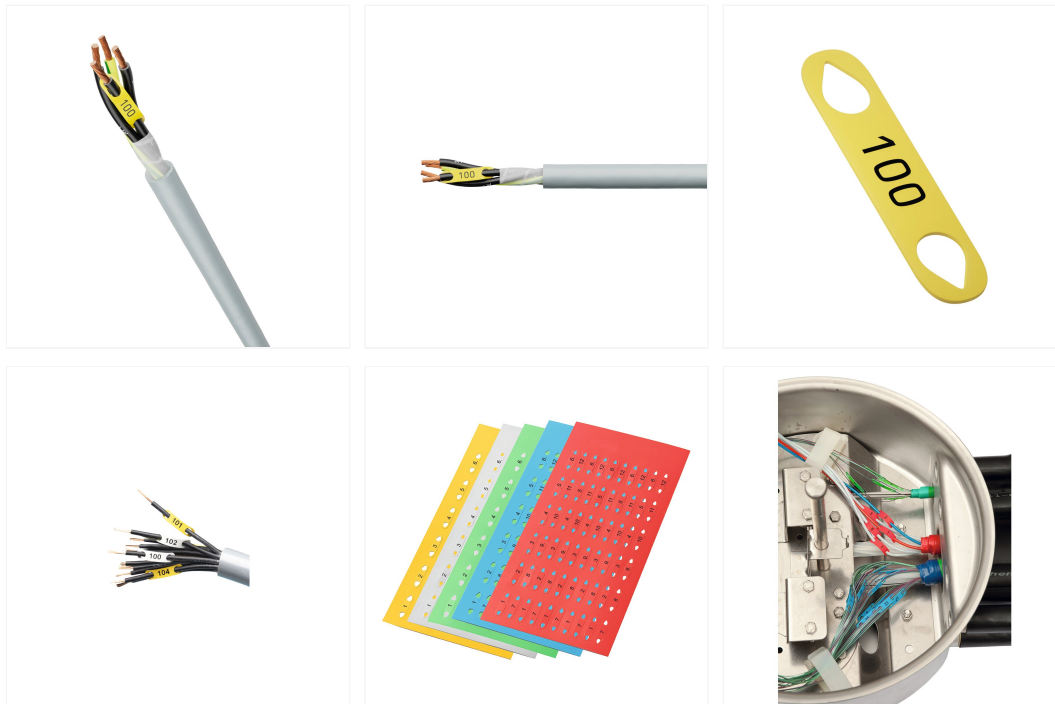

### Details

#### Notes

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

#### Remarks

LF1 contained in FLEXIMARK® sample bag (article no. M3251010).

---

Green, blue and red are available upon request

Sheet size: 80-100mm (3.12-3.9 in) x 210mm

Printable with the FLEXIMARK® software and a commercial laser printer.

You can download the free full version of our FLEXIMARK® software in the "Printers and software" section under the "Guide" tab. Please use the following link: <https://www.lapp.com/de/de/produkte/kennzeichnungssysteme/drucker-und-software/c/114041>

## Technical Data

### General information

Brand	FLEXIMARK®
Product type	Laser printing label
Type of packaging	Cardboard packaging Small packaging
Delivery Unit	1
pieces per PU	600 pc.
Number of pages per PU	10
Number of labels per side	60
Mounting method	push on
Printable with	Laser Printer
Printing procedure	Laser Printing
Time of installation	Before installation
Marking for	Conductors Fiber optic cables Cables
Industry segment	Healthcare & Pharma

### Electrical parameters

#### Product design

Number of characters	7
Label type	Cable Label
width printable area	0.441 in
Overall width	0.906 in

---

Overall height	0.205 in
Thickness	0.007 in
For cross-section (min.)	0.75 mm <sup>2</sup>
For cross-section (max.)	1.5 mm <sup>2</sup>
Material label	Polyester
Colour description	yellow

---

**Product features**

Flame-retardant	No
UV-resistant	Yes
Acid-resistant	No
Alkali resistant	Yes
Halogenfree	Yes
Oil resistant	Yes
Waterproof	Yes
Self-adhesive	No

---

**Certifications and standards**

CE marking	No
UL recognized	No
UL listed	No
Ecolab certified	No

---

**FLEXIMARK® Flexiprint LF**

Article No.	Name	For cross-section (min.)	For cross-section (max.)	width printable area	Number of characters	pieces per PU
83254410	Flexiprint LF0 0.25-0.75 YE	0.25 mm <sup>2</sup>	0.75 mm <sup>2</sup>	0.516 in	7	600 pc.
83254416	Flexiprint LF0 0.25-0.75 WH	0.25 mm <sup>2</sup>	0.75 mm <sup>2</sup>	0.516 in	7	600 pc.
83254420	Flexiprint LF1 0.75-1.5 YE	0.75 mm <sup>2</sup>	1.5 mm <sup>2</sup>	0.441 in	7	4,500 pc.
83254430	Flexiprint LF1 0.75-1.5 YE	0.75 mm <sup>2</sup>	1.5 mm <sup>2</sup>	0.441 in	7	600 pc.
83254436	Flexiprint LF1 0.75-1.5 WH	0.75 mm <sup>2</sup>	1.5 mm <sup>2</sup>	0.441 in	7	600 pc.
83254440	Flexiprint LF1L 0.75-1.5 YE	0.75 mm <sup>2</sup>	1.5 mm <sup>2</sup>	0.866 in	15	2,250 pc.
83254447	Flexiprint LF1L 0.75-1.5 YE	0.75 mm <sup>2</sup>	1.5 mm <sup>2</sup>	0.866 in	15	300 pc.
83254460	Flexiprint LF1B 1.5-2.5 YE	1.5 mm <sup>2</sup>	2.5 mm <sup>2</sup>	0.441 in	7	4,500 pc.
83254470	Flexiprint LF1B 1.5-2.5 YE	1.5 mm <sup>2</sup>	2.5 mm <sup>2</sup>	0.441 in	7	600 pc.
83254476	Flexiprint LF1B 1.5-2.5 WH	1.5 mm <sup>2</sup>	2.5 mm <sup>2</sup>	0.441 in	7	600 pc.
83254500	Flexiprint LF2 2.5-6.0 YE	2.5 mm <sup>2</sup>	6 mm <sup>2</sup>	0.433 in	7	4,500 pc.
83254510	Flexiprint LF2 2.5-6.0 YE	2.5 mm <sup>2</sup>	6 mm <sup>2</sup>	0.433 in	7	300 pc.
83254520	Flexiprint LF3 6.0-16.0 YE	6 mm <sup>2</sup>	16 mm <sup>2</sup>	0.669 in	7	2,250 pc.
83254530	Flexiprint LF3 6.0-16.0 YE	6 mm <sup>2</sup>	16 mm <sup>2</sup>	0.669 in	7	200 pc.
83280005	LF0 YE fl-print 0.25-0.75mm YE	0.25 mm <sup>2</sup>	0.75 mm <sup>2</sup>	0.516 in	7	4,500 pc.

V1.1