


**LCK 45 25x142.5mm WH 160st**

**Article No.:** 83256149

Laser printing label; Cable diameter: 0.315in - 1.417in; white; Polyester

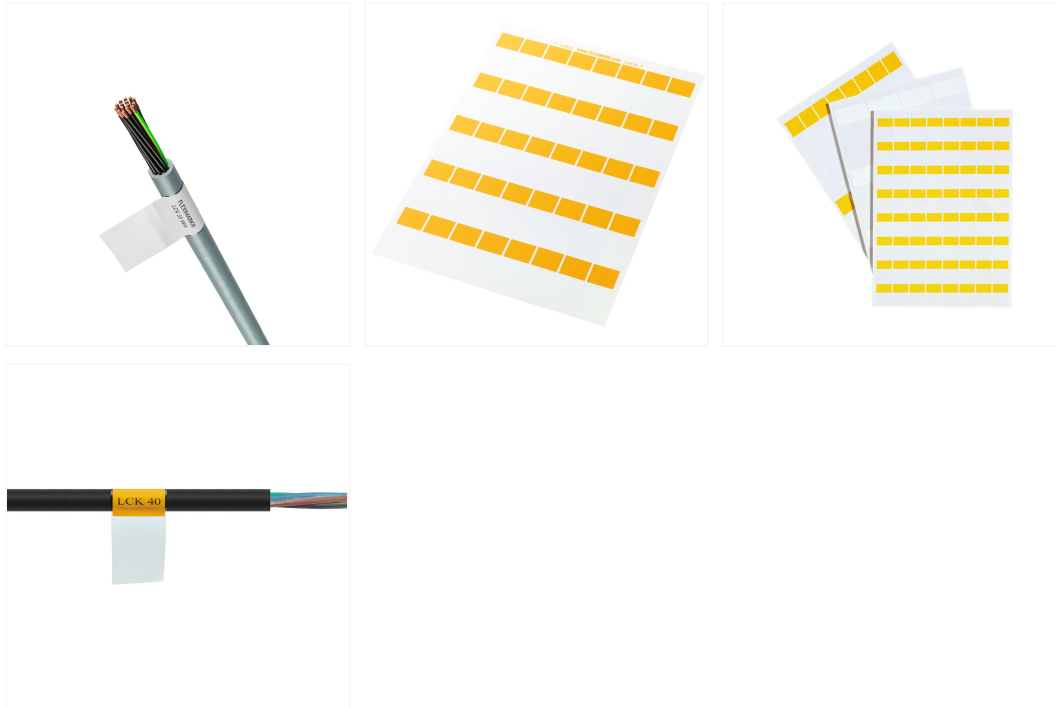

**Details**

**Benefits**

- Self-adhesive and therefore easy to attach.
- Space-saving due to the tight wrapping of the cable.
- Transparent foil section of the label wraps the printed text and protects it against external influences.
- Withstands temperatures from -40°C to +125°C, as well as humidity.
- Available in small or large packaging.

**Application**

- Can be used universally for professional marking and labeling of cables.
- Printable with the FLEXIMARK® software (templates available) and a commercial laser printer (best printing results with straight sheet insertion).
- Suitable for outdoor use.

---

**Notes**

Unless specified otherwise, the product values shown are rated values at room temperature. You can receive additional values, such as tolerances, upon request if they are available and have been released for publication.

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

If applicable, the prices are solid metal prices without additional charges and VAT. Sales only to business customers.

**Remarks**

LCK 32 YE included in FLEXIMARK® sample bag (article no. M3251010).

Insert sheets into the manual feed compartment.

Printable with the FLEXIMARK® software and a commercial laser printer.

You can download the free full version of our FLEXIMARK® software in the "Printers and software" section under the "Guide" tab. Please use the following link: <https://www.lapp.com/de/de/produkte/kennzeichnungssysteme/drucker-und-software/c/114041>

**Technical Data****General information**

Brand	FLEXIMARK®
Product type	Laser printing label
Type of packaging	Cardboard packaging Small packaging
Delivery Unit	1
Number of pages per PU	10
Format size	DIN A4
Number of labels per side	16
Mounting method	wind
Printable with	Laser Printer
Printing procedure	Laser Printing

Marking for	Conductors Fiber optic cables Cables Conduits
Industry segment	Energy Healthcare & Pharma Lifts & Elevators Ships & boats Solar

### Electrical parameters

#### Product design

Label type	Wrapping Label
width printable area	0.984 in
labeling area height	1 in
Glue	Acrylic-based
Overall width	0.984 in
Overall height	5.61 in
Thickness	0.001 in
For min. cable outer diameter	0.315 in
For max. cable outer diameter	1.417 in
Material label	Polyester
Perforated	Yes
Colour description	white

#### Product features

Installation temperature min.	10 °C
Flame-retardant	No
UV-resistant	Yes
UV-resistant according to	EN ISO 4892-2, method A (color change permitted)
Chemical resistant	Yes
Acid-resistant	Yes

---

Alkali resistant	Yes
Halogenfree	Yes
Oil resistant	Yes
salt water resistant	Yes
Waterproof	Yes
Self-adhesive	Yes

---

**Certifications and standards**

CE marking	No
UL recognized	No
UL listed	No
Ecolab certified	No

---

**FLEXIMARK® Wrapping labels LCK**

Article No.	Name	For min. cable outer diameter	For max. cable outer diameter	Colour description	width printable area	labeling area high	pieces per PU	Number of pages per PU
83256142	LCK 32 25x35.5mm YE	0.157 in	0.276 in	yellow	0.984 in	0.5 in		10
83256143	Label LCK 32 25x33.5mm WH	0.157 in	0.276 in	white	0.984 in	0.5 in		10
83256144	LCK 35 25x55mm YE	0.236 in	0.472 in	yellow	0.984 in	0.748 in		10
83256145	LCK 35 25x55 WH, 400 st/fp	0.236 in	0.472 in	white	0.984 in	0.748 in		10
83256146	LCK 40 25x94mm YE	0.315 in	0.827 in	yellow	0.984 in	1 in		10
83256147	LCK 40 25x94mm WH	0.315 in	0.827 in	white	0.984 in	1 in		10
83256148	LCK 45 25x142.5mm YE	0.315 in	1.417 in	yellow	0.984 in	1 in		10
83256149	LCK 45 25x142.5mm WH 160st	0.315 in	1.417 in	white	0.984 in	1 in		10
83256150	LCK 60 50x56mm YE	0.236 in	0.472 in	yellow	1.969 in	0.748 in		10
83256151	LCK 60 50x56mm WH	0.236 in	0.472 in	white	1.969 in	0.748 in		10
83256152	LCK 65 50x94mm YE	0.315 in	0.827 in	yellow	1.969 in	1 in		10
83256153	LCK 65 50x94mm WH	0.315 in	0.827 in	white	1.969 in	1 in		10
83256154	LCK 70 50x142.5mm YE	0.315 in	1.417 in	yellow	1.969 in	1 in		10
83256155	LCK 70 50x142.5mm WH	0.315 in	1.417 in	white	1.969 in	1 in		10
83256160	LCK 48 35x93mm WH	0.315 in	0.827 in	white	1.378 in	1 in		10
83256161	LCK 48 35x93mm YE	0.315 in	0.827 in	yellow	1.378 in	1 in		10

V1.1